


タンダレス・インサートサイズ

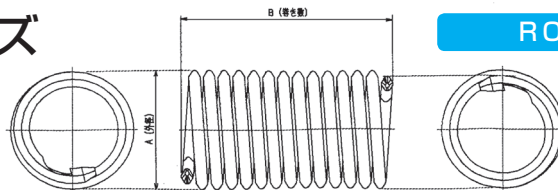

ROHS指令適合品

材質：SUS304（ばね用ステンレス鋼線）

区分	サイズ	呼び長さ	製品コード	外径	巻数(±0.25巻)	適用ドリル径
メトリック並目ねじ用	M2-0.4	1D	2TNM-M2×0.4-1D	2.50~2.79	3.250	2.1
		1.5D	2TNM-M2×0.4-1.5D		5.625	
		2D	2TNM-M2×0.4-2D		8.000	
	M2.5-0.45	1D	2TNM-M2.5×0.45-1D	3.20~3.70	3.375	2.6
		1.5D	2TNM-M2.5×0.45-1.5D		5.750	
		2D	2TNM-M2.5×0.45-2D		8.125	
	M2.6-0.45	1D	2TNM-M2.6×0.45-1D	3.30~3.60	3.875	2.8
		1.5D	2TNM-M2.6×0.45-1.5D		6.375	
		2D	2TNM-M2.6×0.45-2D		8.875	
	M3-0.5	1D	2TNM-M3×0.5-1D	3.80~4.35	3.750	3.1
		1.5D	2TNM-M3×0.5-1.5D		6.375	
		2D	2TNM-M3×0.5-2D		8.875	
	M4-0.7	1D	2TNM-M4×0.7-1D	5.05~5.60	3.625	4.2
		1.5D	2TNM-M4×0.7-1.5D		6.125	
		2D	2TNM-M4×0.7-2D		8.625	
	M5-0.8	1D	2TNM-M5×0.8-1D	6.20~6.80	4.125	5.2
		1.5D	2TNM-M5×0.8-1.5D		6.875	
		2D	2TNM-M5×0.8-2D		9.625	
	M6-1.0	1D	2TNM-M6×1.0-1D	7.40~7.95	4.000	6.3
		1.5D	2TNM-M6×1.0-1.5D		6.750	
		2D	2TNM-M6×1.0-2D		9.500	
	M8-1.25	1D	2TNM-M8×1.25-1D	9.80~10.35	4.500	8.4
		1.5D	2TNM-M8×1.25-1.5D		7.375	
		2D	2TNM-M8×1.25-2D		10.250	
M10-1.5	1D	2TNM-M10×1.5-1D	11.95~12.50	4.875	10.5	
	1.5D	2TNM-M10×1.5-1.5D		8.000		
	2D	2TNM-M10×1.5-2D		11.125		
M12-1.75	1D	2TNM-M12×1.75-1D	14.30~15.00	5.000	12.5	
	1.5D	2TNM-M12×1.75-1.5D		8.250		
	2D	2TNM-M12×1.75-2D		11.500		
ユニファイ並目ねじ用	U2-56	1D	2TNC-2-56×1D	2.79~3.02	3.000	2.3
		1.5D	2TNC-2-56×1.5D		5.250	
		2D	2TNC-2-56×2D		7.375	
	U4-40	1D	2TNC-4-40×1D	3.66~4.03	2.750	3.0
		1.5D	2TNC-4-40×1.5D		4.750	
		2D	2TNC-4-40×2D		6.750	
	U6-32	1D	2TNC-6-32×1D	4.52~4.90	2.750	3.7
		1.5D	2TNC-6-32×1.5D		4.750	
		2D	2TNC-6-32×2D		6.875	
	U8-32	1D	2TNC-8-32×1D	5.21~5.58	3.500	4.4
		1.5D	2TNC-8-32×1.5D		6.000	
		2D	2TNC-8-32×2D		8.375	
	U10-24	1D	2TNC-10-24×1D	6.20~6.57	2.875	5.1
		1.5D	2TNC-10-24×1.5D		5.000	
		2D	2TNC-10-24×2D		7.125	
	U1/4-20	1D	2TNC-1/4-20×1D	7.88~8.38	3.375	6.7
		1.5D	2TNC-1/4-20×1.5D		5.750	
		2D	2TNC-1/4-20×2D		8.000	
NEW U5/16-18	1D	2TNC-5/16-18×1D	9.65~10.16	4.000	8.4	
	1.5D	2TNC-5/16-18×1.5D		6.625		
	2D	2TNC-5/16-18×2D		9.250		
NEW U3/8-16	1D	2TNC-3/8-16×1D	11.48~11.99	4.375	10	
	1.5D	2TNC-3/8-16×1.5D		7.250		
	2D	2TNC-3/8-16×2D		10.000		
ユニファイ細目ねじ用	U10-32	1D	2TNF-10-32×1D	6.00~6.50	4.125	5.0
		1.5D	2TNF-10-32×1.5D		6.875	
		2D	2TNF-10-32×2D		9.500	
	U1/4-28	1D	2TNF-1/4-28×1D	7.77~8.28	5.000	6.6
		1.5D	2TNF-1/4-28×1.5D		8.250	
		2D	2TNF-1/4-28×2D		11.375	
	NEW U5/16-24	1D	2TNF-5/16-24×1D	9.65~10.16	5.500	8.3
		1.5D	2TNF-5/16-24×1.5D		8.875	
		2D	2TNF-5/16-24×2D		12.250	
	NEW U3/8-24	1D	2TNF-3/8-24×1D	11.38~11.89	6.875	9.9
		1.5D	2TNF-3/8-24×1.5D		11.000	
		2D	2TNF-3/8-24×2D		15.000	

* 通常在庫品です。

* 販売数量・価格に関してはお問い合わせください。