


GRACE INERTIA 2.5

TE Internal #: 3-1903390-4  
Rectangular Connector Housings, Wire-to-Wire, 4 Position, .098 in [2.5 mm] Centerline, 1 Row, PBT GF, Plug, Socket, Wire & Cable, GRACE INERTIA 2.5

[View on TE.com >](#)

Connectors > Rectangular Connectors > Rectangular Connector Housings > STD Temp Sig GRACE INERTIA Plug

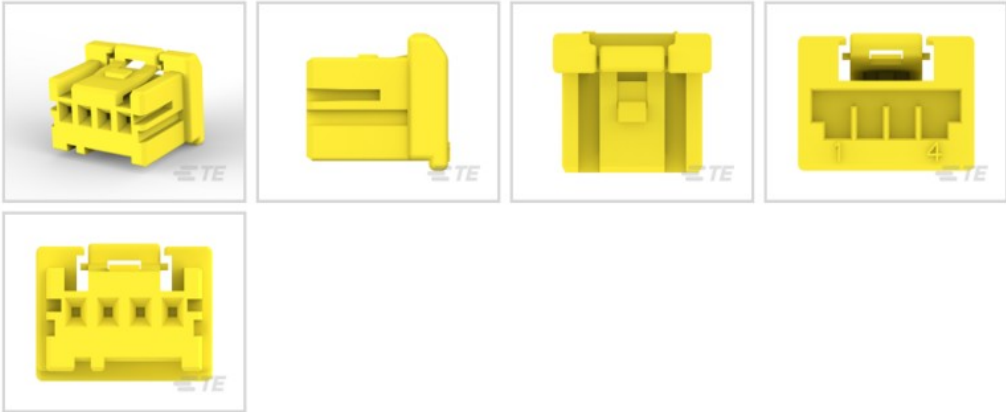

Connector System: Wire-to-Wire  
Number of Positions: 4  
Centerline (Pitch): 2.5 mm [ .098 in ]  
Number of Rows: 1  
Housing Material: PBT GF  
[All STD Temp Sig GRACE INERTIA Plug \(63\)](#)

Features

Product Type Features

Connector System	Wire-to-Wire
Connector & Housing Type	Plug
Sealable	No
Connector & Contact Terminates To	Wire & Cable

Configuration Features

Number of Cavities	4
Number of Positions	4
Number of Rows	1

Electrical Characteristics

Operating Voltage	250 VAC
-------------------	---------

Contact Features

Contact Layout	Inline
----------------	--------