

Polishing Equipments

■ Feature

- The alkali resistance of this sandpaper ensures sufficient polishing strength even when it is used with soap and water.

■ Specification

- Dimensions : 230×280mm



WATER-RESISTANT SANDPAPER


Particle size	Order No.	2- 995		Ref.No
		1 bag (10 sheets) JPY	Order No. JPY	
# 120	N-07	¥ 690	N-57 ¥ 5,460	024570
# 180	N-08	¥ 690	N-58 ¥ 5,460	024570
# 240	N-09	¥ 690	N-59 ¥ 5,460	024570
# 320	N-10	¥ 690	N-60 ¥ 5,460	024570
# 400	-01	¥ 690	N-51 ¥ 5,460	024570
# 600	-02	¥ 690	N-52 ¥ 5,460	024570
# 800	-03	¥ 690	N-53 ¥ 5,460	024570
#1000	-04	¥ 780	N-54 ¥ 6,350	024570
#1200	-05	¥ 870	N-55 ¥ 7,250	024570
#1500	N-11	¥ 870	N-61 ¥ 7,250	024570
#2000	N-12	¥ 1,040	N-62 ¥ 8,900	024570
#3000	-06	¥ 1,240	N-56 ¥ 11,000	024570

WATER-RESISTANT SANDPAPER(D Type)

Order No.	Model No.	Particle size	Quantity	JPY	Ref.No
3-1827-01	DCCS #120	# 120	1 box (100 sheets)	¥ 5,400	024575
3-1827-02	DCCS #150	# 150		¥ 5,400	024575
3-1827-03	DCCS #180	# 180		¥ 5,400	024575
3-1827-04	DCCS #240	# 240		¥ 5,400	024575
3-1827-05	DCCS #320	# 320		¥ 5,400	024575
3-1827-06	DCCS #400	# 400		¥ 5,400	024575
3-1827-07	DCCS #600	# 600		¥ 5,400	024575
3-1827-08	DCCS #800	# 800		¥ 5,400	024575
3-1827-09	DCCS #1000	#1000		¥ 6,700	024575
3-1827-10	DCCS #1500	#1500		¥ 7,500	024575

- Specification ● Dimensions : 230×280mm ● Abrasive particles : silicone carbide

- Applications ● Polishing all coated surfaces on vehicles or metal parts

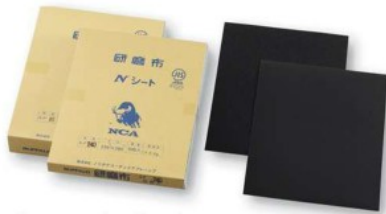

Polishing Cloth Sheet(N Sheet)

Order No.	Model No.	Particle size	Quantity	JPY	Ref.No
3-1843-01	A 60	# 60	1 box (50 sheets)	¥ 6,000	024555
3-1843-02	A 80	# 80		¥ 5,640	024555
3-1843-03	A100	#100		¥ 5,400	024555
3-1843-04	A150	#150		¥ 5,400	024555
3-1843-05	A240	#240		¥ 5,400	024555
3-1843-06	A320	#320		¥ 5,400	024555
3-1843-07	A400	#400		¥ 5,400	024555

■ Feature

- This flexible cloth sheet contains gelatine.

- Specification ● Dimensions : 230×280mm

- Abrasive particles : abrasive alundum particles

■ Applications

- Rust removal ● Metal polishing in dry manual operations

Waterproof Sheet

Order No.	Model No.	Particle size	Quantity	JPY	Ref.No
3-1841-01	C120 C947H	# 120	1 box (100 sheets)	¥ 4,700	024575
3-1841-02	C150 C947H	# 150		¥ 4,700	024575
3-1841-03	C180 C947H	# 180		¥ 4,700	024575
3-1841-04	C240 C947H	# 240		¥ 4,700	024575
3-1841-05	C320 C947H	# 320		¥ 4,700	024575
3-1841-06	C400 C947H	# 400		¥ 4,700	024575
3-1841-07	C600 C947H	# 600		¥ 4,700	024575
3-1841-08	C800 C947H	# 800		¥ 4,700	024575
3-1841-09	C1000 C947H	#1000		¥ 5,700	024575
3-1841-10	C1500 C947H	#1500		¥ 6,200	024575

- Specification ● Dimensions : 228×280mm ● Abrasive particles : silicone carbide

- Applications ● Polishing base surfaces and coating surfaces of metal products

- Rust and dirt removal ● Preparing woodwork material and polishing coating surfaces

- Feature ● Polyester film coating with even thickness superfine particles enables fine and beautiful finished surfaces. ● These products are highly resistant to water and oil, and applicable to both dry and wet treatment. ● Suitable for polishing of precision equipment parts and precise finish polishing of various parts and materials.



WRAPPING FILM ABRASIVES

JP

Order No.	Model No.	Material	Particle Size (Micron (μ)/Mesh)	Color	JPY	Ref. No	
2-7697-01	A3-305HT	Alumina Oxide	30.0/# 600	Yellowish Green	¥ 550	024535	
2-7697-02	S3-15SHT	Silicon Carbide	15.0/# 1000	Gray	¥ 550	024535	
2-7697-03	A3-12SHT	Alumina Oxide	12.0/# 1200	Yellow	¥ 550	024535	
2-7697-04	A3-9SHT		9.0/# 2000	Sky Blue	¥ 550	024535	
2-7697-05	A3-5SHT		5.0/# 3000	Brown	¥ 550	024535	
2-7697-06	A3-3SHT		3.0/# 4000	Peach	¥ 550	024535	
2-7697-07	A3-1SHT		1.0/# 8000	Light Green	¥ 550	024535	
2-7697-08	C3-0.5SHT		Chromium Oxide	0.5/#10000	Dark Green	¥ 550	024535
2-7697-09	A3-0.3SHT		Alumina Oxide	0.3/#15000	Light Gray	¥ 550	024535

- Specification ● Dimensions : 216×280mm ● Thickness : 75 micron ● Quantity : 1sheet

Dry Sanding Sheet

Order No.	Model No.	Particle size	Quantity	JPY	Ref.No
3-1842-01	C100 A10D	#100	1 box (100 sheets)	¥ 6,600	024555
3-1842-02	C120 A10D	#120		¥ 5,300	024555
3-1842-03	C150 A10D	#150		¥ 5,300	024555
3-1842-04	C180 A10D	#180		¥ 5,300	024555
3-1842-05	C240 A10D	#240		¥ 5,300	024555
3-1842-06	C320 A10D	#320		¥ 5,300	024555
3-1842-07	C400 A10D	#400		¥ 5,300	024555

■ Specification

- Dimensions : 228×280mm ● Abrasive particles : silicone carbide

- Applications ● Polishing base surfaces and coating surfaces of metal products

- Rust and dirt removal ● Preparing woodwork material and polishing coating surfaces