

# FLWチューブ



## 耐摩擦性に優れた編組チューブです

- 耐摩擦性に非常に優れ、屋外用での線材やホースの保護に最適です。
- 伸縮性に富み、摩擦抵抗も低いために裂傷や擦傷に強く、装着もスムーズです。
- 特に油や海水などの浸食に強く、引張強度もありフレキシブルなため、エンジン周囲や船舶の可動部分保護にも最適です。

## BRAIDED TUBE WHICH IS SUPERIOR IN FRICTION-RESISTANT


- It is superior in friction-resistant and suitable for the protection of a wiring and hose as outdoor using.
- FLW tube is good for stretchy and can put in place smoothly because sliding is strong by laceration and scratch.
- This tube is especially strong by erosion such as oil and seawater.
- It has Tensile Strength and flexibility and suitable for the protection of movable things such as near engine and a ship.

## Specifications

材質 Material	ポリエチレンテレフタレート Polyethylene Terephthalate
使用温度範囲 Operating Temperature	-70~125℃
融点 Melting point	250℃
色 Color	黒 Black
規格 Standard	UL (File No. E347759) CSA



船舶のエンジン周りに広く使用されています。  
It is widely used around engines of ship.

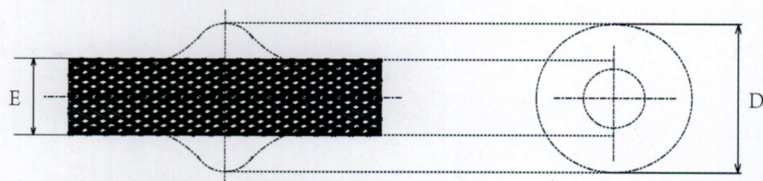

型番 Order Ref. Number	自然径 Natural occasion diameter width (mm) E	拡大最大径 Enlarged greatest dimension (mm) D	重量 Weight (g/m)	包装単位 Standard length(m/spool)
FLW-9	約10.0	約20.0	12.6	150
FLW-25	約25.0	約38.0	28.5	75
FLW-35	約13.0	約50.0	45.0	75
FLW-45	約51.0	約75.0	51.0	60
FLW-70	約76.0	約100.0	63.5	30
FLW-100	約102.0	約140.0	98.3	30