



EPV/APV L型二通
Union Elbow

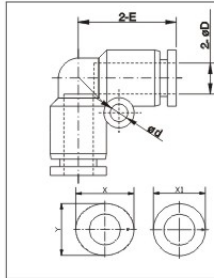


| 型号/MODEL | ΦD | Φd | E | X | Y | X1 | C |
|----------|----|-----|------|------|------|------|------|
| EPV4 | 4 | — | 17.5 | 11.9 | 10.5 | 10 | 14.9 |
| EPV6 | 6 | 3.3 | 18.8 | 13.9 | 12.5 | 12 | 15.5 |
| EPV8 | 8 | 3.3 | 22.5 | 15.9 | 13.9 | 14 | 17.8 |
| EPV10 | 10 | 4.3 | 27.2 | 19.5 | 17 | 17 | 20.5 |
| EPV12 | 12 | 4.3 | 29.3 | 23 | 20.5 | 20 | 22.9 |
| EPV16 | 16 | 4.3 | 32.5 | 27 | 24 | 23.5 | 24 |

EPE/APE T型三通
Union Tee

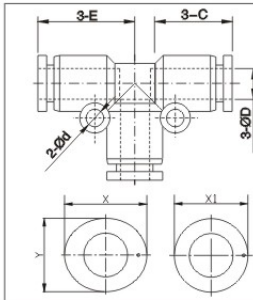


| 型号/MODEL | ΦD | Φd | E | X | Y | X1 | C |
|----------|----|-----|------|------|------|------|------|
| EPE4 | 4 | 3.3 | 18.5 | 11.9 | 10.5 | 10 | 15.4 |
| EPE6 | 6 | 3.3 | 19 | 13.9 | 12.5 | 12 | 15.3 |
| EPE8 | 8 | 3.3 | 22.5 | 15.9 | 13.9 | 14 | 17.8 |
| EPE10 | 10 | 4.3 | 27.9 | 19.5 | 17 | 17 | 21 |
| EPE12 | 12 | 4.3 | 29.3 | 23 | 20.5 | 20 | 22.9 |
| EPE16 | 16 | 4.3 | 32.5 | 27 | 24 | 23.5 | 24 |

EPEG/APEG T型减径三通A
Diff.Diam. Union Tee A

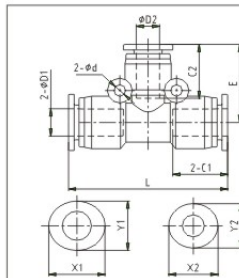


| 型号/MODEL | ΦD1 | ΦD2 | C1 | C2 | Φd | E | L | X1 | Y1 | X2 | Y2 |
|-----------|-----|-----|------|------|-----|------|------|------|------|------|------|
| EPEG6-4 | 6 | 4 | 15.5 | 15.4 | 3.3 | 19 | 38.1 | 13.9 | 12.5 | 11.9 | 10.5 |
| EPEG8-4 | 8 | 4 | 17.8 | 15.4 | 3.3 | 22 | 44.9 | 15.9 | 13.9 | 11.9 | 10.5 |
| EPEG8-6 | 8 | 6 | 17.8 | 16 | 3.3 | 22.1 | 44.9 | 15.9 | 13.9 | 13.9 | 12.5 |
| EPEG10-6 | 10 | 6 | 21 | 16 | 4.3 | 27.1 | 55.8 | 19.5 | 17 | 13.9 | 12.5 |
| EPEG10-8 | 10 | 8 | 21 | 17.8 | 4.3 | 27.5 | 55.8 | 19.5 | 17 | 15.9 | 13.9 |
| EPEG12-8 | 12 | 8 | 22.9 | 17.8 | 4.3 | 28.5 | 58.6 | 23 | 20.5 | 15.9 | 13.9 |
| EPEG12-10 | 12 | 10 | 22.9 | 21 | 4.3 | 28.9 | 58.6 | 23 | 20.5 | 19.5 | 17 |
| EPEG16-12 | 16 | 12 | 24 | 22.9 | 4.3 | 31.8 | 65 | 27 | 24 | 23 | 20.5 |

EPEW/APEW T型减径三通B
Diff.Diam. Union Tee B

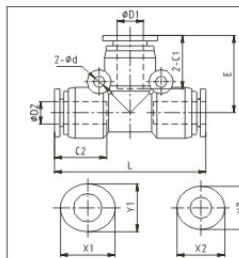

| 型号/MODEL | ΦD1 | ΦD2 | C1 | C2 | Φd | E | L | X1 | Y1 | X2 | Y2 |
|-----------|-----|-----|------|------|-----|------|------|------|------|------|------|
| EPEW6-4 | 6 | 4 | 15.5 | 15.4 | 3.3 | 19.1 | 38 | 13.9 | 12.5 | 11.9 | 10.5 |
| EPEW8-4 | 8 | 4 | 17.8 | 15.4 | 3.3 | 22.5 | 43.9 | 15.9 | 13.9 | 11.9 | 10.5 |
| EPEW8-6 | 8 | 6 | 17.8 | 15.5 | 3.3 | 22.5 | 44 | 15.9 | 13.9 | 13.9 | 12.5 |
| EPEW10-6 | 10 | 6 | 21 | 15.5 | 4.3 | 27.9 | 54.1 | 19.5 | 17 | 13.9 | 12.5 |
| EPEW10-8 | 10 | 8 | 21 | 17.8 | 4.3 | 27.9 | 55 | 19.5 | 17 | 15.9 | 13.9 |
| EPEW12-8 | 12 | 8 | 22.9 | 17.8 | 4.3 | 29.3 | 57 | 23 | 20.5 | 15.9 | 13.9 |
| EPEW12-10 | 12 | 10 | 22.9 | 21 | 4.3 | 29.3 | 57.8 | 23 | 20.5 | 19.5 | 17 |
| EPEW16-12 | 16 | 12 | 24 | 22.9 | 4.3 | 32.5 | 63.6 | 27 | 24 | 23 | 20.5 |

EPY/APY Y型三通
Union Y

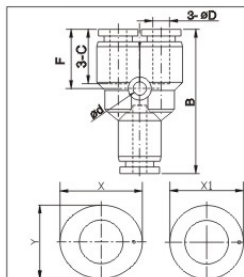

| 型号/MODEL | ΦD | Φd | B | F | C | X | Y | X1 |
|----------|----|-----|------|------|------|------|------|------|
| EPY4 | 4 | 3.3 | 35.5 | 14 | 14.9 | 11.9 | 10.5 | 10 |
| EPY6 | 6 | 3.3 | 36.6 | 14.8 | 15.5 | 13.9 | 12.5 | 12 |
| EPY8 | 8 | 3.3 | 39.8 | 17.8 | 17.3 | 15.9 | 13.5 | 14 |
| EPY10 | 10 | 4.3 | 48.9 | 20.6 | 20 | 19.5 | 17 | 17 |
| EPY12 | 12 | 4.3 | 52.6 | 21.3 | 22.9 | 23 | 20.5 | 20 |
| EPY16 | 16 | 5.1 | 61 | 22.5 | 24 | 27 | 24 | 23.5 |

