


15MPa B型銅管くい込継手  
(150kgf/cm<sup>2</sup>)

**GO型**

**SLEEVE**



JIS H3250 C3604BD-F

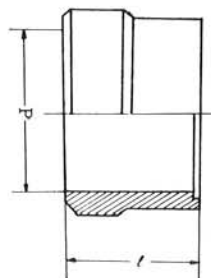

単位：mm

継手の呼称 Designation of joints	適用する管外径 P Tube (O.D)	ℓ
GO-4-B	4	7
GO-6-B	6	9
GO-8-B	8	9
GO-10-B	10	10
GO-12-B	12	10
GO-14-B	14	10
GO-15-B	15	10
GO-16-B	16	10
GO-18-B	18	10
GO-20-B	20	10
GO-22-B	22	10
GO-25-B	25	11
GO-28-B	28	11
GO-30-B	30	11
GO-32-B	32	11
GO-35-B	35	14
GO-40-B	40	14