


3.5MPa (35kgf/cm²) B1型銅管くい込継手


GU-1型 B1 UNION

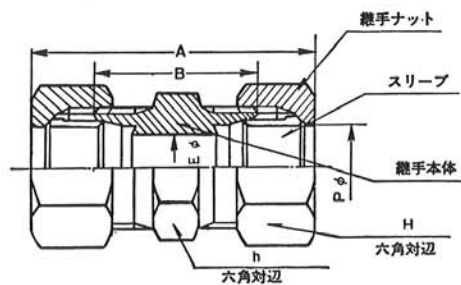

単位：mm

呼称 Designation of Joints	P	A	B	E	h	H
4-B1	4	35	20	2.5	8	10
6-B1	6	38	22	4	10	12
8-B1	8	39	23	6	12	14
10-B1	10	42	25	8	14	17
12-B1	12	46	26	10	17	19
14-B1	14	46	27	11	21	23
15-B1	15	46	27	12	21	23
20-B1	20	50	30	17	26	29
25-B1	25	54	34	20	20	36

GC型 B1 MALE CONNECTOR

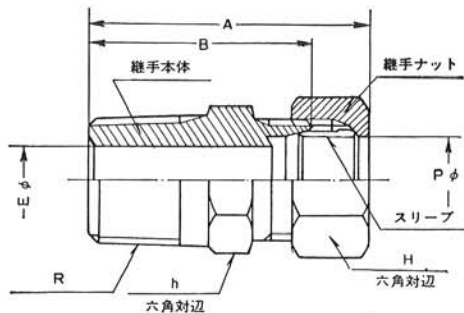

単位：mm

呼称 Designation of Joints	P	R	A	B	E	h	H
4 × 1/8	4	1/8	31	23	2.5	10	10
6 × 1/8	6	1/8	32	24	4	10	12
6 × 1/4	6	1/4	37	29	4	14	12
6 × 3/8	6	3/8	38	30	4	17	12
※ 6 × 1/2	6	1/2	44.5	37	4	23	12
8 × 1/8	8	1/8	33	25	4	12	14
8 × 1/4	8	1/4	37	29	6	14	14
8 × 3/8	8	3/8	38	30	6	17	14
※ 8 × 1/2	8	1/2	45	37	6	23	14
10 × 1/8	10	1/8	35	26	4	14	17
10 × 1/4	10	1/4	38	30	6	14	17
10 × 3/8	10	3/8	39	31	8	17	17
※ 10 × 1/2	10	1/2	46	37	8	23	17
12 × 1/4	12	1/4	39	31	6	17	19
12 × 3/8	12	3/8	40	32	8.5	17	19
※ 12 × 1/2	12	1/2	46	37	10	23	19
14 × 3/8	14	3/8	43	33	8.5	21	23
14 × 1/2	14	1/2	47	37	11	23	23
15 × 3/8	15	3/8	43	33	8.5	21	23
15 × 1/2	15	1/2	47	37	12	23	23
20 × 1/2	20	1/2	48	39	12	26	29
20 × 3/4	20	3/4	51	42	17	29	29
25 × 3/4	25	3/4	53	43	17	32	36
25 × 1"	25	1"	56	46	20	35	36

※印は標準品外

NPT ネジ在庫有り