



Air Hose

Paintings for Building · Automobile · Portable Air Tool

Soft NEW FLEX Air Hose

E-SNF


- E-SNF excels in flexibility, improving work efficiency.
- The surface of the hose is smooth and the hose is hard to get stuck anywhere.
- Because of polyurethane resin, E-SNF has higher flexibility and resistance to cold even at low temperature.

EIGHTRON®

Non-PVC



RoHS Compliant

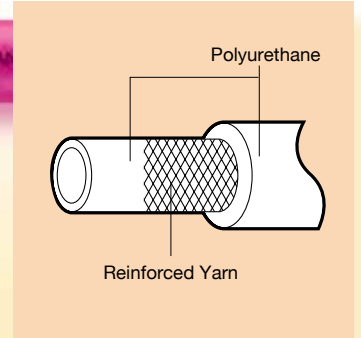

Model Number	I.D. × O.D.		Working Pressure (MPa)		Minimum Bend Radius (20°C) mm	Temperature Range °C	Standard Length m	Weight g/m	Package Type	Color
	mm		at 20°C	at 60°C						
E-SNF-6.5	6.5 × 10		0 ~ 1.5	0 ~ 0.6	40	-20 ~ 60	10	55	Film Wrapping	Pink Purple
							20			
							30			
							50			
E-SNF-8.5	8.5 × 12.5		0 ~ 1.5	0 ~ 0.6	55	-20 ~ 60	10	80	Film Wrapping	Pink Purple
							20			
							30			
							50			
							100		Paper Bobbin	

*E-SNF hoses work best when it is used with fitting protectors.

Soft NEW FLEX Push-to-Connect Products

RoHS Compliant



Model Number	Hose Size	Length	Fittings
	I.D. × O.D. (mm)	m	
E-SNF-6.5-RC-10M	6.5 × 10	10	E-RSS-65P (Socket) + E-RSP-65P (Plug)
E-SNF-6.5-RC-20M		20	
E-SNF-6.5-RC-30M		30	
E-SNF-8.5-RC-10M	8.5 × 12.5	10	E-RSS-85P (Socket) + E-RSP-85P (Plug)
E-SNF-8.5-RC-20M		20	
E-SNF-8.5-RC-30M		30	

*SOFT NEW FLEX Push-to-Connect Products are available on request. Please contact us for delivery time.

Joints For Air Hose (Push-to-Connect Joint)

RoHS Compliant

- Socket and Plug are connectable without effort.
- The spring part prevents the twisting of the hose due to the rotary function.
- Lock function of the socket prevents the hose from hooking off the plug.

Type	Image	Code	Hose Size	Material	Weight (g/piece)
			I.D. × O.D. (mm)		
Socket		E-RSS-65P	6.5 × 10	Steel Chrome Plating	150
		E-RSS-85P	8.5 × 12.5		170
Plug		E-RSP-65P	6.5 × 10		95
		E-RSP-85P	8.5 × 12.5		95

*Please refer to page 23 for how to install the push-to-connect joint to the hose.