



# GUIDING OPTIONS FOR SLIDING DOORS


## ASSEMBLY EXAMPLES

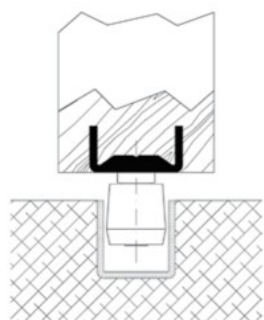


GUIDE ROLLER WITH  
BOTTOM BRACKET,  
NYLON OR BRASS  
(.N00 or .M00)

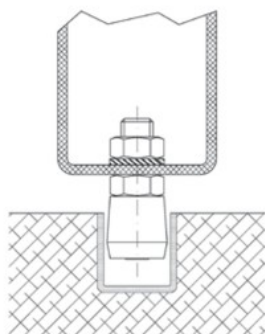


GUIDE ROLLER WITH  
SCREW, NYLON OR  
BRASS  
(.N49 or .M49)

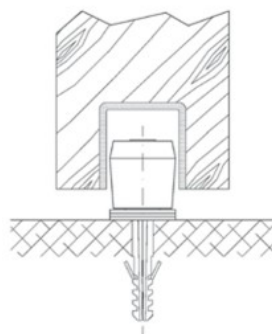


GUIDE ROLLER WITH  
FIXING PLUG, NYLON  
OR BRASS  
(.N58 or .M58)

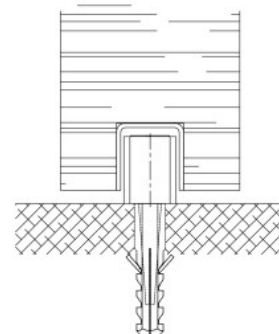

GUIDE WITH NYLON  
PIECE (.U54)

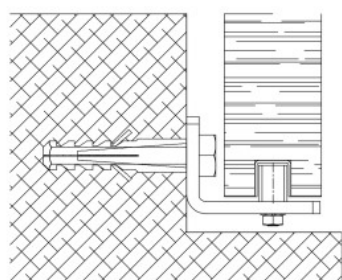


GUIDE WITH NYLON  
PIECE WITH COR-  
NER BRACKET  
(.U53)

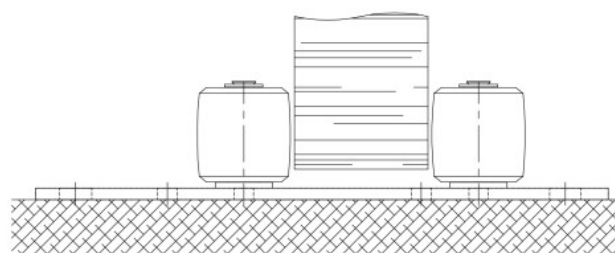

DOUBLE GUIDE ROLLER WITH BASE PLATE  
(.X65/66)

NIKO Guide track No.	Dimensions		
	h (mm)	B (mm)	s (mm)
32.000	15	15	1
33.000	25	25	2
34.000	40	40	3
35.000	50	60	4

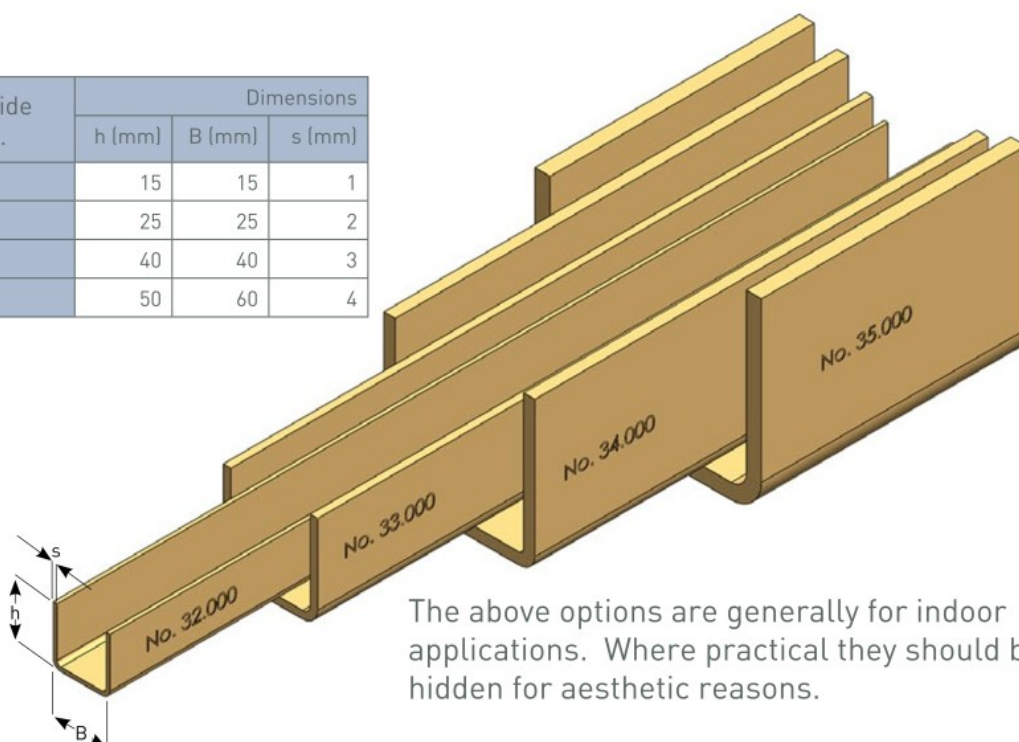

The above options are generally for indoor applications. Where practical they should be hidden for aesthetic reasons.