



BI-LoK	DLH	Elbow Adapter Connects fractional tubes
---------------	------------	---

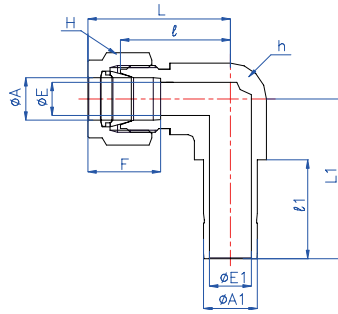

H : See dimensional data(Last page)

Part No.	A (Tube O. D)		A ₁ (Tube O. D)		E	E ₁	h (Flat)		l	l ₁	L	L ₁	F
	in	mm	in	mm	mm	mm	in	mm	mm	mm	mm	mm	mm
DLH 4-4	1/4	6.35	1/4	6.35	4.8	4.6	5/8	15.9	19.8	16.5	27.3	26.2	15.4
DLH 5-5	5/16	7.94	5/16	7.94	6.4	6.4	5/8	15.9	22.4	17.2	29.9	26.9	16.3
DLH 6-6	3/8	9.53	3/8	9.53	7.1	7.1	5/8	15.9	23.1	18.0	30.6	27.7	17.0
DLH 8-8	1/2	12.7	1/2	12.7	10.4	9.9	13/16	20.6	26.2	23.5	36.5	39.9	23.0

BI-LoK	DRE	Reducer Connects fractional tube to metric BI-LOK port
---------------	------------	--

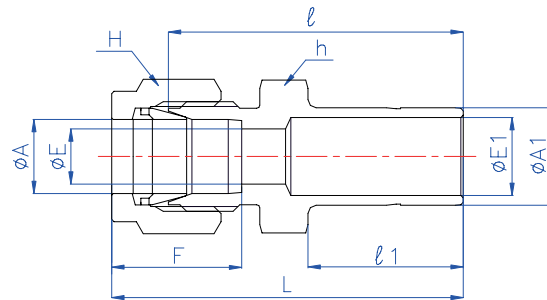

H : See dimensional data(Last page)

Part No.	A (Tube O. D)		A ₁	E	E ₁	h (HEX)		l	l ₁	L	F
	in	mm	mm	mm	mm	in	mm	mm	mm	mm	mm
DRE 1-6M	1/16	1.59	6	1.3	4.0	7/16	11.11	28.7	16.5	32.7	8.9
DRE 2-6M	1/8	3.18	6	2.3	4.0	7/16	11.11	30.2	16.5	36.9	13.0
DRE 4-3M	1/4	6.35	3	4.8	1.5	1/2	12.7	29.7	14.0	37.2	15.4
DRE 4-6M	1/4	6.35	6	4.8	4.0	1/2	12.7	32.6	16.5	40.1	15.4
DRE 6-6M	3/8	9.53	6	7.1	4.0	5/8	15.88	34.8	16.5	42.3	17.0
DRE 6-10M	3/8	9.53	10	7.1	8.0	5/8	15.88	36.3	18.0	43.8	17.0
DRE 8-12M	1/2	12.7	12	10.4	9.5	13/16	20.64	43.3	23.5	53.6	23.0