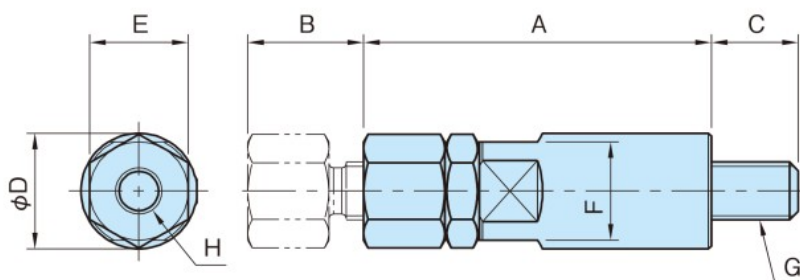


BJ333**SMALL SCREW JACKS****Body**

Steel (S45C)
Black oxide finish

Part Number	A	B	C	D	E	F	G	H	Load Capacity (N)	Weight (g)
BJ333-08040	40	10	12	16	13	13	M 8×1.25	M 6×1 6-deep	2,600	55
BJ333-08050	50	20								70
BJ333-10050	50	10	14.5	20	17	17	M10×1.5	M 8×1.25 8-deep	3,900	110
BJ333-10060	60	20								135
BJ333-12065	65	15	19.5	24	22	22	M12×1.75	M10×1.50 10-deep	5,900	220
BJ333-12080	80	30								275
BJ333-16080	80	15	24.5	32	27	27	M16×2	M12×1.75 12-deep	11,000	460
BJ333-16095	95	30								555
BJ333-20100	100	20	29.5	35	30	30	M20×2.5	M16×2 16-deep	18,000	740
BJ333-20120	120	30								900

How to use:

Adjustable support that accepts a tip on top.

