

CP131


COMPACT ID HOLDING CLAMPS



CP131-A



CP131-B

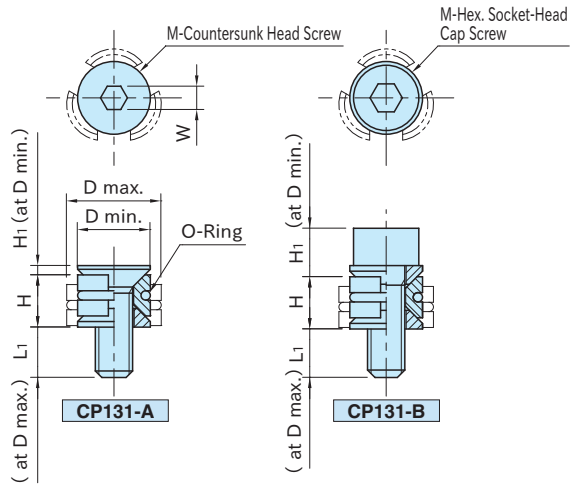

Jaw	Washer	O-Ring
SNM439 steel Black oxide finished HRC33-39	SCM435 steel Black oxide finished	Fluoro rubber

Part Number	D		H		H ₁	M	L ₁	W
	min.	max.	D min.	D max.				
CP131-04001A	8	10.3	5.5	4.6	0.9	M4×0.7 -12L	7.3	2.5
CP131-05001A	10	12.3	6.4	5.6	1.1	M5×0.8 -15L	9.1	3
CP131-06001A	12	16.3	8.6	7	1.3	M6×1 -18L	11.2	4
CP131-08001A	16	22	11.5	9.4	1.6	M8×1.25-25L	16.2	5
CP131-04001B	8	10.3	5.5	4.6	5.1	M4×0.7 -12L	7.1	3
CP131-05001B	10	12.3	6.4	5.6	6.2	M5×0.8 -15L	9	4
CP131-06001B	12	16.3	8.6	7	7.9	M6×1 -18L	10.6	5
CP131-08001B	16	22	11.5	9.4	10.4	M8×1.25-25L	15.4	6

Part Number	Clamping Force (kN)	Allowable Screw Torque (N·m)	Weight (g)
CP131-04001A	0.9	2.1	3
CP131-05001A	1.5	4.3	5
CP131-06001A	2.1	7.3	9
CP131-08001A	4	18	22
CP131-04001B	1.5	2.7	4
CP131-05001B	2.5	5.4	7
CP131-06001B	5	9.1	11
CP131-08001B	9	25	28