



EBG-SOFT

ERGOSTYLE SOFT-TOUCH BALL KNOBS



ELESA Original Design EBK.

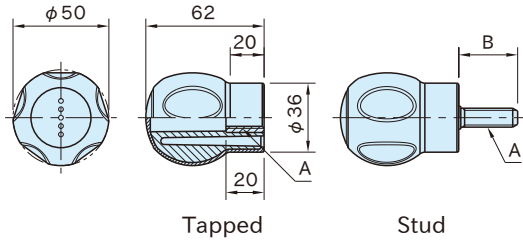

Body	Insert	Stud
 Polypropylene plastic Coated with thermoplastic elastomer Shore A 70 Black matte	Brass	Steel (S10C) Zinc plated

Insert

Part Number	A	Weight (g)
EBG50 -SOFT	M 8×1.25	79
EBG50A-SOFT	M10×1.5	76

- Elastomer coating helps to dampen vibrations.

Stud

Part Number	A	B	Weight (g)
EBG50 ×16-SOFT	M 8×1.25	16	80
EBG50 ×20-SOFT		20	86
EBG50 ×25-SOFT		25	91
EBG50 ×30-SOFT	M10×1.5	30	97
EBG50A×20-SOFT		20	110
EBG50A×25-SOFT		25	116
EBG50A×30-SOFT		30	122
EBG50A×50-SOFT		50	143

- Working temperature : Between 0°C and 80°C