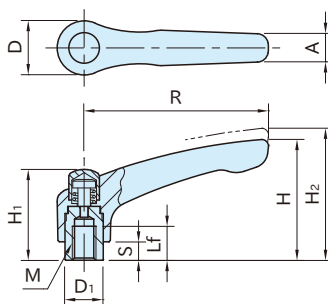
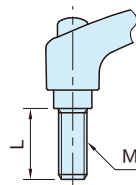


FKFP-SUS
(Tapped)FKRP-SUS
(Stud)FKFP-SUS
(Tapped)FKRP-SUS
(Stud)

Type	Handle	Cap/Locking
FKFP-SUS	Stainless steel (SCS13 equivalent to SUS304)	Stainless steel (SUS303)
FKRP-SUS	Electropolished finish	

Type/Size	Teeth	R	H	D	H ₁	H ₂	M	D ₁	S	A
FKFP-SUS	6	20	65	42.5	19	32	45.5	13.5	6.5	10
	8									
FKRP-SUS	10	22	80	54.5	22	41.5	58.5	16	10	11

Features:

Protective cap is attached by press-fit into the handle, so it does not gather dust and dirt.
All made from stainless steel, for excellent corrosion resistance.
Perfect for use on food processing machines etc. where frequent cleaning is required.

Technical Information

Tightening Capacity

Type/Size	FKRP-SUS		
	6	8	10
Thread Diameter	M6	M8	M10
Turning Radius (mm)	55	55	70
Load Capacity (N)	120	290	445
Allowable Tightening Force (N)	4300	8000	12800

Turning Radius

