

KN-SOFT

SOFT-TOUCH FLUTED GRIP KNOBS




ELESA Original Design MBT-SOFT.




Tapped




Stud

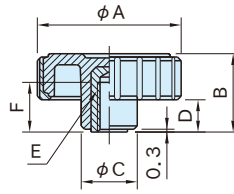

Tapped

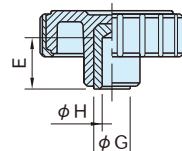

Plain

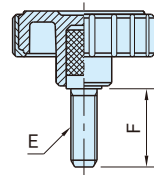

Stud

Knob	Insert	Stud
Polypropylene plastic Thermoplastic elastomer coated Shore A70 Black matte	Brass	Steel (SUM22L) Zinc plated

Size	A	B	C	D	
KN-SOFT	45	44	24	17	10
	55	54	30	20	12.5

Plain

Part Number	E	G	H (H9)	Weight (g)
KN45RSOFT	14	12	6	32
KN55RSOFT	20	15	8	40

Tapped

Part Number	E	F	Weight (g)
KN45ASOFT	M 6×1	12	31
KN45 SOFT	M 8×1.25	13	30
KN55ASOFT		20	46
KN55 SOFT	M10×1.5	18	44

Stud

Part Number	E	F	Weight (g)
KN45A×10SOFT	M 6×1	10	25
KN45A×20SOFT		20	30
KN45 ×16SOFT	M 8×1.25	16	33
KN45 ×30SOFT		30	37
KN45 ×50SOFT		50	47
KN55A×16SOFT	M 8×1.25	16	40
KN55A×30SOFT		30	50
KN55A×50SOFT		50	64
KN55 ×20SOFT	M10×1.5	20	52
KN55 ×30SOFT		30	57
KN55 ×50SOFT		50	73

- Elastomer coating helps to dampen vibrations, for comfortable gripping.
- Working temperature : Between 0°C and 90°C