

MH4 / MH5 ALUMINUM EQUIPMENT HANDLES



MH4
(Cranked, Aluminum)



MH5
(Straight, Aluminum)





MH4-S
(Cranked, Steel)




MH5-S
(Straight, Steel)

Type	Body
MH4 MH5	Aluminum (A6N01S) Anodized finish Satin finish Black matte
MH4-S MH5-S	Steel (SUM22L) Hard chrome plated finish Satin finish Natural matte

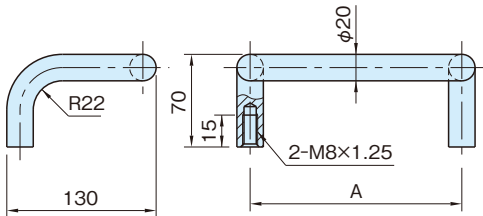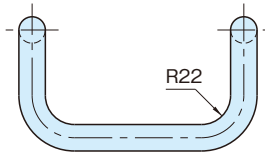

MH4 **MH4-S**
(Cranked)

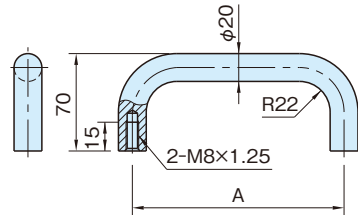

MH5 **MH5-S**
(Straight)

MH4 **MH4-S** (Cranked)

Aluminum		Steel		A	Load Capacity (N)
Part Number	Weight (g)	Part Number	Weight (g)		
MH4-200	390	MH4-200S	1,160	200	1000
MH4-350	520	MH4-350S	1,260	350	

MH5 **MH5-S** (Straight)

Aluminum		Steel		A	Load Capacity (N)
Part Number	Weight (g)	Part Number	Weight (g)		
MH5-200	240	MH5-200S	690	200	1000
MH5-250	280	MH5-250S	870	250	
MH5-300	320	MH5-300S	940	300	
MH5-350	370	MH5-350S	1,060	350	
MH5-400	420	MH5-400S	1,180	400	