




**OVG**





**OVG1**





**OVG2**

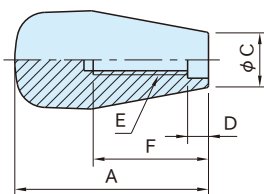


**OVG**

  

**OVG1**

  

**OVG2**

 

Body
Phenolic plastic
Glossy Finish
Black

**OVG**

Part Number	A	B	C	D	E	F	Weight (g)
<b>OVG65</b>	67	34	19	8	M10×1.5	40	56
<b>OVG85</b>	86		20	7		48	72

**OVG1**

Part Number	A	B	C	D	E	F	Weight (g)
<b>OVG1-70</b>	69	29	14	10	M 8×1.25	45	37
<b>OVG1-70A</b>				15	M10×1.5		35
<b>OVG1-80</b>	79	35	17	12	M12×1.75	55	60

**OVG2**

Part Number	A	B	C	D	E	F	Weight (g)
<b>OVG2-40</b>	40	24	14	3.5	M 8×1.25	28	14
<b>OVG2-50</b>	47	29	16				25
<b>OVG2-50A</b>				24			
<b>OVG2-60</b>	60	35	19	8	M10×1.5	35	46

· Working temperature : Between -20°C and 110°C