


# PKN LIFT KNOBS



ELESsa Original Design I.150, P.131

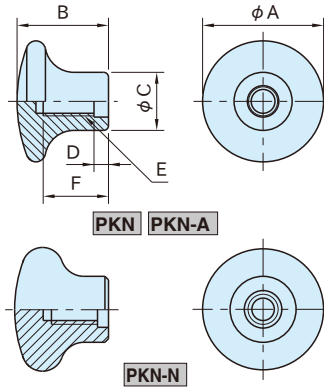

Body
Phenolic plastic
Glossy Finish
Black

Part Number	A	B	C	D	E	F	Weight (g)
<b>PKN25A</b>	25	19	12	3	M 5×0.8	10	6
<b>PKN25</b>					M 6×1		5
<b>PKN30A</b>	32	23	15		M 8×1.25	16	13
<b>PKN30</b>							12
<b>PKN35N</b>	34	24.5	19	3.5	M10×1.5	15	16
<b>PKN45N</b>	44	34	24	4		20	36

• Working temperature : Between -20°C and 110°C