


シム・スペーサー
エンドプレート

品番 (例) FWS-70-50-7-20-8-30-0.1-LM

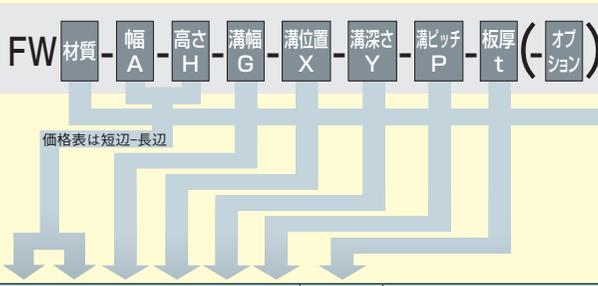

シム・スペーサー

ワッシャー

エンドプレート

指定0.1mm単位		短辺		長辺		溝幅 G		溝位置 X		溝深さ Y		溝ピッチ P		板厚 t		価格(円)／枚													
																		鉄 FW [F]		焼入鋼 FW [Y]		ステンレス FW [S]		真鍮 FW [B]		アルミ FW [A]			
															0.05							650	520	600	480				
															0.1~0.5	550	440	800	640	650	520	600	480	550	440				
															0.6~1.0	750	600	1,000	800	850	680	800	640	750	600				
															1.2~2.3	800	640	1,200	960	950	760	1,100	880	800	640				
															2.5~3.2	850	680			1,050	840			900	720				
															4.0~4.5	950	760			1,200	960								
															5.0~6.0	1,050	840			1,450	1,160								
															0.05					750	600	750	600						
															0.1~0.5	650	520	950	760	750	600	750	600	700	560				
															0.6~1.0	850	680	1,150	920	950	760	950	760	900	720				
															1.2~2.3	900	720	1,350	1,080	1,050	840	1,250	1,000	950	760				
															2.5~3.2	950	760			1,150	920			1,050	840				
															4.0~4.5	1,050	840			1,300	1,040								
															5.0~6.0	1,150	920			1,550	1,240								
															0.05					900	720	900	720						
															0.1~0.5	800	640	1,100	880	900	720	900	720	850	680				
															0.6~1.0	1,000	800	1,300	1,040	1,100	880	1,100	880	1,050	840				
															1.2~2.3	1,050	840	1,700	1,360	1,200	960	1,400	1,120	1,100	880				
															2.5~3.2	1,100	880			1,300	1,040			1,200	960				
															4.0~4.5	1,200	960			1,450	1,160								
															5.0~6.0	1,300	1,040			1,700	1,360								
						3		3		0		4.5			0.05					1,050	840	1,050	840						
															0.1~0.5	950	760	1,250	1,000	1,050	840	1,050	840	900	720				
															0.6~1.0	1,150	920	1,500	1,200	1,300	1,040	1,250	1,000	1,150	920				
															1.2~2.3	1,200	960	2,100	1,680	1,400	1,120	1,600	1,280	1,200	960				
															2.5~3.2	1,250	1,000			1,550	1,240			1,300	1,040				
															4.0~4.5	1,350	1,080			1,700	1,360								
															5.0~6.0	1,550	1,240			2,300	1,840								
															0.05					900	720	900	720						
															0.1~0.5	800	640	1,100	880	900	720	900	720	850	680				
															0.6~1.0	1,000	800	1,300	1,040	1,100	880	1,100	880	1,050	840				
															1.2~2.3	1,050	840	1,700	1,360	1,200	960	1,400	1,120	1,100	880				
															2.5~3.2	1,100	880			1,300	1,040			1,200	960				
															4.0~4.5	1,200	960			1,450	1,160								
															5.0~6.0	1,300	1,040			1,700	1,360								
															0.05					1,150	920	1,100	880						
															0.1~0.5	900	720			1,150	920	1,100	880	950	760				
															0.6~1.0	1,150	920			1,400	1,120	1,350	1,080	1,200	960				
															1.2~2.3	1,200	960			1,500	1,200	1,700	1,360	1,250	1,000				
															2.5~3.2	1,300	1,040			1,700	1,360			1,400	1,120				
															4.0~4.5	1,400	1,120			1,900	1,520								
															5.0~6.0	1,700	1,360			2,700	2,160								

セミオーダー