



BN

ニップル

Male connector

黄銅製

Brass

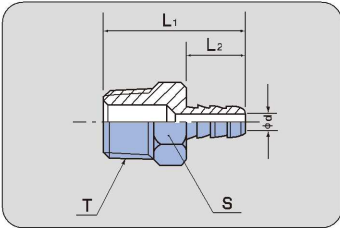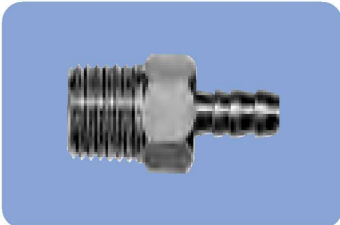

| 部品番号 PART NO. | 適用チューブ TUBE SIZE TO BE USED 外径×内径 O.D. (mm) X I.D. (mm) | T (R·M) | φd (mm) | L ₁ (mm) | L ₂ (mm) | S 六角対辺 HEX (mm) | 重量 WEIGHT (g) | 有効断面積 EFFECTIVE SECTIONAL AREA (mm ²) |
|--------------------|---|------------|------------|------------------------|------------------------|--------------------------|---------------------|---|
| BN-4×2.5-M5-BSN | 4×2.5 | M5 | 1.4 | 18.0 | 8 | 8 | 3 | 1.0 |
| BN-4×2.5-PT1/8-BSN | 4×2.5 | 1/8 | 1.5 | 21.0 | 8 | 10 | 6 | 1.3 |
| BN-6×4 -M5-BSN | 6×4 | M5 | 2.2 | 18.0 | 8 | 8 | 4 | 3.3 |
| BN-6×4 -PT1/8-BSN | 6×4 | 1/8 | 3.0 | 21.0 | 8 | 10 | 6 | 5.0 |
| BN-6×4 -PT1/4-BSN | 6×4 | 1/4 | 3.0 | 24.5 | 8 | 14 | 15 | 6.7 |


BL

エルボ

Male elbow

黄銅製

Brass

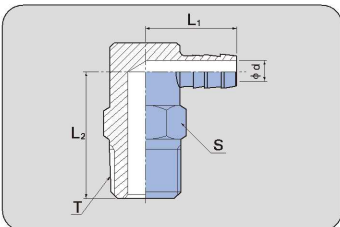

| 部品番号 PART NO. | 適用チューブ TUBE SIZE TO BE USED 外径×内径 O.D. (mm) X I.D. (mm) | T (R·M) | φd (mm) | L ₁ (mm) | L ₂ (mm) | S 六角対辺 HEX (mm) | 重量 WEIGHT (g) | 有効断面積 EFFECTIVE SECTIONAL AREA (mm ²) |
|--------------------|---|------------|------------|------------------------|------------------------|--------------------------|---------------------|---|
| BL-4×2.5-M5-BSN | 4×2.5 | M5 | 1.4 | 12.9 | 15.0 | 10 | 10 | 1.1 |
| BL-4×2.5-PT1/8-BSN | 4×2.5 | 1/8 | 1.4 | 12.9 | 18.0 | 10 | 11 | 1.2 |
| BL-6×4 -M5-BSN | 6×4 | M5 | 2.9 | 12.9 | 15.0 | 10 | 10 | 3.3 |
| BL-6×4 -PT1/8-BSN | 6×4 | 1/8 | 2.9 | 12.9 | 18.0 | 10 | 12 | 4.2 |
| BL-6×4 -PT1/4-BSN | 6×4 | 1/4 | 2.9 | 12.9 | 21.5 | 14 | 20 | 4.0 |


BLD

二連エルボ

Double male elbow

黄銅製

Brass

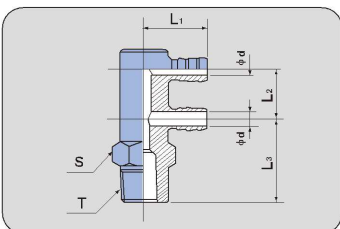

| 部品番号 PART NO. | 適用チューブ TUBE SIZE TO BE USED 外径×内径 O.D. (mm) X I.D. (mm) | T (R) | φd (mm) | L ₁ (mm) | L ₂ (mm) | L ₃ (mm) | S 六角対辺 HEX (mm) | 重量 WEIGHT (g) | 有効断面積 EFFECTIVE SECTIONAL AREA (mm ²) |
|-----------------------|---|----------|------------|------------------------|------------------------|------------------------|--------------------------|---------------------|---|
| BLD-4×2.5-2-PT1/8-BSN | 4×2.5 | 1/8 | 1.4 | 12.9 | 10 | 18 | 10 | 16.0 | 1.6 |
| BLD-6×4 -2-PT1/8-BSN | 6×4 | 1/8 | 2.9 | 12.9 | 10 | 18 | 10 | 18.5 | 4.9 |