

スモールノブ SK, SK-sus, SK-F

Small Knobs SK, SK-sus, SK-F

RoHS指令適合品




SK

SK-sus

SK-F

材表 ノブ knob : 黒色ナイロン樹脂PA6 Nylon plastic Black
 ネジ screw : 鋼線SWCH・三価クロメート Steel Trivalent Chromate
 ネジ screw : ステンレスSUS303 Stainless
 メネジ female screw : 黄銅C3604B Brass

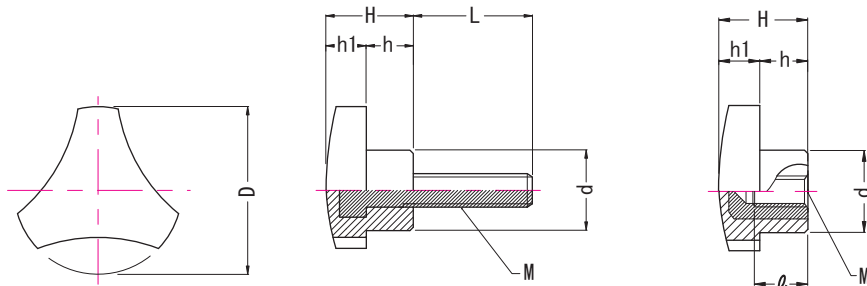

Unit : mm

品番	M	L	D	d	H	h	h1	(g)
SK- 6-A	M 6×P1.0	15	26	14.5	10	5	5	10
SK- 6		25	30	17	19	10	9	15
SK- 8-A	M 8×P1.25	15	40	21	21	11	10	25
SK- 8-B×15		25						30
SK- 8-B (×25)		30						34
SK- 8-B×30	M10×P1.5	25	40	21	21	11	10	45
SK-10 (×25)		30						48
SK-10×30								

Unit : mm

品番	M	L	D	d	H	h	h1	(g)
SK- 6 -sus	M 6×P1.0	25	30	17	19	10	9	15
SK- 8-A-sus	M 8×P1.25		40	21	21	11	10	25
SK- 8-B-sus			40	21	21	11	10	30
SK-10 -sus	M10×P1.5		40	21	21	11	10	45

Unit : mm

品番	M	ℓ	D	d	H	h	h1	(g)
SK-6-F	M 6×P1.0	11	40	21	21	11	10	13
SK-8-F	M 8×P1.25							15

注意事項 使用温度 max80°C min-20°C