

朝顔型 PN P-N、平型ハンドル車 SN S-N

Offset Handwheels PN,P-N

Flat Handwheels SN,S-N


RoHS指令適合品



PN



P-N + AS

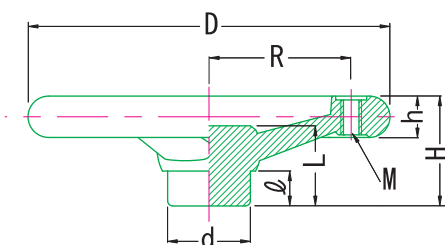


P-N Type



SN



S-N + AS

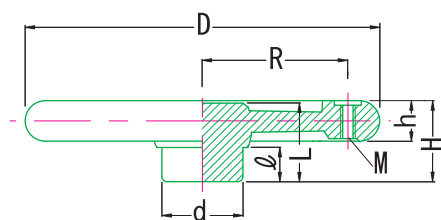

S-N Type

材 鋳鉄FC200 cast iron

表 クロムメッキ chrome plated

追加工詳細 P.271~P.272参照

握りネジ付き

推奨グリップ

鋼製握り 詳細 P.225参照

鋼製回転握り 詳細 P.228参照

品番	品番	M	品番	品番
P- 50-N		M 4 × P0.7	AS-10	-
P- 63-N				
P- 80-N	S- 80-N	M 5 × P0.8	AS-13	C-13
P-100-N	S-100-N			
P-125-N	S-125-N	M 6 × P1.0	AS-16	C-16
P-140-N	S-140-N			
P-150-N	S-150-N	M 8 × P1.25	AS-20	C-20
P-160-N	S-160-N			
P-180-N	S-180-N	M10 × P1.5	AS-25	C-25
P-200-N	S-200-N			
P-224-N	S-224-N	M12 × P1.75	AS-32	C-32
P-250-N	S-250-N			
P-280-N	S-280-N	M16 × P2.0	AS-36	C-36
P-300-N	S-300-N			
P-315-N	S-315-N			
P-355-N	S-355-N			
P-400-N	S-400-N			
P-450-N	S-450-N			
P-500-N	S-500-N			
P-630-N	S-600-N			

グリップ詳細 P.151~P.172参照