


Cover

This cover is made from transparent polycarbonate, and set-in type. For TX100 or greater models, 3P dedicated products are also available. TT10SK type can be attached to upper stage only, TT20K and TTJ8N types can be attached to both of upper stage and lower stage.

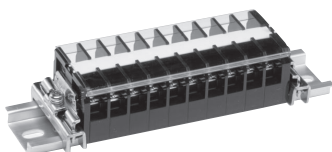

When the cover is attached

Type name	Applicable unit	Width x length (mm)	General mass (g)	Number of contents
TXB 1	TXS20, TN13SBK, TN12BK, TN13BK,	37 × 500	25	5 pieces
TXB 1 L	TN20BK, TEU11	37 × 1000	50	5 pieces
TXB 2	TX7, TX10S, TX10, TX20, TXU7, TXU10S,	38 × 500	19	5 pieces
TXB 2 L	TXU10, TXU20, For 2-stage terminal block upper stage (TT20K, TT20UK, TTG40, TTG40U)	38 × 1000	38	5 pieces
TRB 1	TR10K	35.5 × 500	24	5 pieces
TRB 1 L		35.5 × 1000	48	5 pieces
TRB 2	TR20K	40 × 500	32	5 pieces
TRB 2 L		40 × 1000	64	5 pieces
TRB 3	TX30, TX50, TXU30, TXU50, TN30BK,	49 × 500	39.5	5 pieces
TRB 3 L	TR30K	49 × 1000	79	5 pieces
TRB 6	TX60, TXU60, TN60BK, TR60K	56 × 500	43	5 pieces
TRB 10 N	TX100, TX150, TXU100, TXW100R, TXW150, TN100K, TR100K	75 × 500	57	5 pieces
TRB 20 N	TX200, TX300, TXW200R, TN200K, TR200K	87 × 500	71	2 pieces
TRB 40 N	TX400, TXW400, TX600, TN400K, TR400K	124 × 500	129	2 pieces
TRB 10 N 03	TX100(3P), TXU100(3P), TR100K(3P)	75 × 85	10	10 pieces
TRB 20 N 03	TX200(3P), TR200K(3P)	87 × 117	17	5 pieces
TRB 30 N 03	TX300(3P)	87 × 138	21	5 pieces
TRB 40 N 03	TX400(3P), TR400K(3P)	124 × 186	46	5 pieces
TRB 60 N 03	TX600(3P)	124 × 192	49	5 pieces
TTB 1 S	TT10SK, TT10SUK	31.5 × 500	21	5 pieces
TTB 1 SL		31.5 × 1000	42	5 pieces
TTB 2	For 2-stage terminal block lower stage (TT20K, TT20UK, TTG20, TTG20U, TTG40, TTG40U, TTJ8N, TTJ8NU)	10.4 × 500	7	5 pieces
TTB 2L		10.4 × 1000	14	5 pieces
TTB 3	TEN11, TEU8, for 2-stage terminal block upper stage (TTG203, TTG2035, TTG20U3, TTG20U35), TEV308	34 × 500	17	5 pieces
TTB 3L		34 × 1000	34	5 pieces
TXJB 7	TXJ7, TEN7, TEV158	24.5 × 500	12	5 pieces
TXJB 7 L		24.5 × 1000	24	5 pieces
TXJB 8	TXJ8, for 2-stage terminal block upper stage (TTJ8N, TTJ8NU), TEN8	29.5 × 500	16	5 pieces
TXJB 8 L		29.5 × 1000	32	5 pieces
T30B	TEU14	45 × 500	33	5 pieces
T30BL		45 × 1000	66	5 pieces

■ Cover of assembled terminal block (part for maintenance)

The cover for assembled terminal block is prepared for part for maintenance.

Applicable terminal block	Cover
T 10	TTB 1S
T 20	The cover for T20 (1m)
T 30	T30 B
TC 60	TRB 6
TC 100	TRB 10N
TC 200	TRB 20N
TC 300B	TCB 3B
TC 450B	TCB 4B
TC 600B	TCB 6B
TL 15	TRB 1
TL 25	TRB 2
TL 35	TRB 3
TC 10S	TTB 1S

■ Insulation barrier

Convenient in preventing short circuit between crimp contacts (poles) when wiring.

Type name	Applicable unit	Material	General mass (g)	Number of contents
TXH 60	TX600, TXM600, TQB400D	Polypropylene	12	2 plates

