

0316 KSS RELEASABLE CABLE TIE




UNIT : mm



Item No.	Length		W	Max.Bundle Dia.	Min LoopTensile Strength		Packing
	mm	inch			lbs	kgs	
RCV-100	102	4"	3.6	25	40	18	100 pcs
RCV-150	150	6"	4.6	39	50	22	
RCV-200	200	8"	4.6	55	50	22	
RCV-250	250	10"	4.8	74	50	22	
RCV-300	300	11 7/8"	4.8	88	50	22	
RCV-370	370	14 9/16"	4.8	102	50	22	
NEW RCV-914	914	36"	9	275	175	80	
RCV-230XL	232.5	8 15/16"	12.8	60	250	114	
RCV-290XL	292.5	11 1/2"	12.8	79	250	114	
RCV-405XL	407.5	16"	12.8	116	250	114	
RCV-480XL	482.5	18 7/8"	12.8	140	250	114	
RCV-580XL	576.6	22 7/8"	12.8	172	250	114	

- Material: UL approved Nylon 66, 94V-2
- Finger catch design to release cable tie locking. Good for temporary fastening purpose.

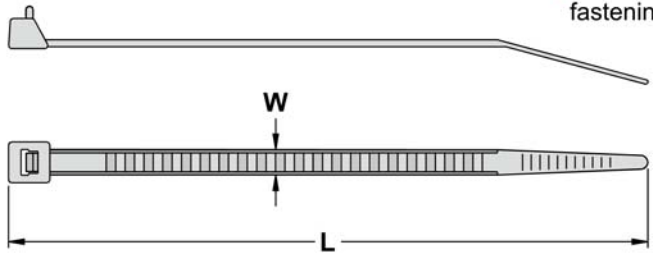

0316 KSS RELEASABLE LASHING CABLE TIE



UNIT : mm



Item No.	Length		W	Max.Bundle Dia.	Min LoopTensile Strength		Packing
	mm	inch			lbs	kgs	
HRCV-240XL	240	9 7/16"	12.8	60	250	114	100 pcs
HRCV-300XL	300	11 7/8"	12.8	79	250	114	
HRCV-415XL	415	16 5/16"	12.8	116	250	114	
HRCV-490XL	490	19 5/16"	12.8	140	250	114	
HRCV-590XL	590	23 1/4"	12.8	170	250	114	

- Material: UL approved Nylon 66, 94V-2
- Finger catch design to release cable tie locking. Good for temporary fastening purpose.

