
 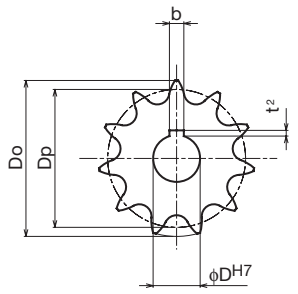


SUSFBN50B

● Order No. Example

SUSFBN 50B 18 D22



- Chain No.50
- Chain Pitch (P)15.875mm
- Roller Link Inner Width (W) 9.53 mm
- Roller Outside Diameter (Dr)10.16 mm
- Tooth Width (T) 8.7 mm

Type	No. of Teeth	Outer Diameter Do	Pitch Diameter Dp	Boss Diameter BD	Boss Length BL	a	Weight kg
SUS FBN 50B	10	58	51.37	★40	25	5	0.27
	11	64	56.35	★45.5	25	5	0.33
	12	69	61.34	★50	25	5	0.41
	13	74	66.34	★51	25	5	0.46
	14	79	71.34	52	25	7	0.52
	15	84	76.35	57	25	7	0.62
	16	89	81.37	62	25	7	0.72
	17	94	86.39	67	25	7	0.83
	18	100	91.42	72	28	8	1.00
	19	105	96.45	73	28	8	1.10
	20	110	101.48	73	28	8	1.20
	21	115	106.51	73	28	8	1.20
	22	120	111.55	73	28	8	1.30
	23	125	116.58	73	28	8	1.30
	24	130	121.62	73	28	8	1.40
	25	135	126.66	73	28	8	1.50
	26	140	131.70	73	28	8	1.50
	28	150	141.79	73	28	8	1.60
	30	161	151.87	73	28	8	1.80
	32	171	161.96	73	28	8	1.90
	35	186	177.10	73	28	8	2.20