


 
100SD



SD Single-Double Sprocket

Order No. Example

100SD 20

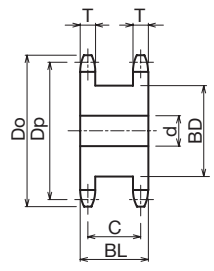

- ChainNo.100
- Chain Pitch(P)31.75mm
- Roller Link Inner Width(W)19.05mm
- Roller Outside Diameter(Dr)19.05mm
- Tooth Width(T)17.6 mm (C)52.4mm

- m Carbon Structural Steel
- h High-frequency Hardened Teeth

Type	No. of Teeth	Outer Diameter Do	Pitch Diameter Dp	Shaft Hole Diameter d			Boss Diameter BD	Boss Length BL	Weight kg	¥	Semi-F ¥
				Prepared Hole Product	Minimum	Maximum					
100SD	12	138	122.67	23	24	58	86	70	4.83		
	13	148	132.67	23	24	65	96	70	5.82		
	14	158	142.68	23	24	75	107	70	6.81		
	15	168	152.71	28	29	80	117	70	7.98		
	16	179	162.74	28	29	85	127	70	9.19		
	17	189	172.79	28	29	96	137	70	9.92		
	18	199	182.84	28	29	106	148	70	11.78		
	19	209	192.90	28	29	110	158	70	13.24		
	20	220	202.96	28	29	115	168	70	14.77		
	21	230	213.03	28	29	125	178	70	15.87		



Sprocket No. and Quantity



* Since we also manufacture sizes other than those in the catalog, and machine shaft holes/keys/taps, etc., depending on your request, please contact our company's sales office for details.



Same-day shipping

* Please refer to P24 to P33 for the Semi-F Series <Complete Product> order method.