
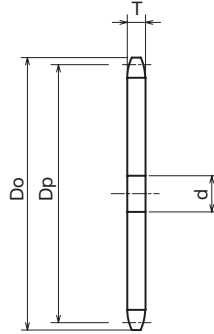


140A

Standard Sprocket A-type

● Order No. Example

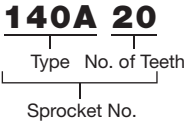

- Chain No.140
- Chain Pitch (P)44.45mm
- Roller Link Inner Width (W)25.40mm
- Roller Outside Diameter (Dr)25.40mm
- Tooth Width (T)23.5 mm

 Common Steel

Type	No. of Teeth	Outer Diameter Do	Pitch Diameter Dp	Shaft Hole Diameter d		Weight kg	¥	Semi-F ¥
				Prepared Hole	Minimum			
140A	10	163	143.84	26	27	2.90		
	11	178	157.78	26	27	3.60		
	12	193	171.74	26	27	4.20		
	13	207	185.74	26	27	4.90		
	14	221	199.76	26	27	5.70		
	15	236	213.79	26	27	6.60		
	16	250	227.84	26	27	7.50		
	17	264	241.91	26	27	8.40		
	18	279	255.98	26	27	9.40		
	19	293	270.06	26	27	10.50		
	20	307	284.15	26	27	11.60		
	21	322	298.24	26	27	12.80		
	22	336	312.34	30	31	14.10		
	23	350	326.44	30	31	15.30		
	24	364	340.54	30	31	16.70		
	25	379	354.65	30	31	18.10		
	26	393	368.77	30	31	19.60		
	28	421	397.00	30	31	23.00		
	30	450	425.24	30	31	26.00		
	32	478	453.49	30	31	29.70		
35	521	495.88	30	31	35.60			
38	563	538.27	30	31	41.90			
40	591	566.54	30	31	46.40			
42	620	594.81	30	31	51.10			
45	662	637.22	30	31	58.80			
48	705	679.63	30	31	66.90			
50	733	707.91	30	31	72.50			
54	790	764.47	35	36	84.60			
60	875	849.32	35	36	104.00			



Sprocket No. and Quantity



* Goods for which the weight of a single item exceeds 30kg
With Sagawa Express/Yamato Transport, products cannot be shipped at any time.



Same-day shipping



* Since we also manufacture sizes other than those in the catalog, and machine shaft holes/taps, etc., depending on your request, please contact our company's sales office for details.

* Please refer to P24 to P33 for the Semi-F Series <Complete Product> order method.