

 
NK140B/NK140C




Standard Sprocket B-type/C-type

● Order No. Example

NK140B 20



Ground Specification Welded Specification

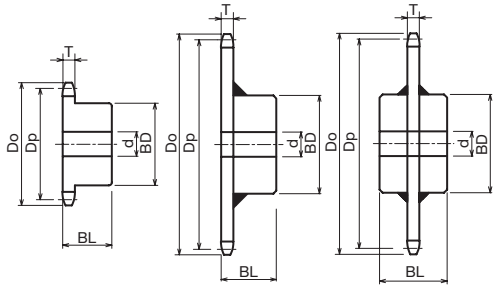

B-Type Ground Specification B-Type Welded Specification C-Type Welded Specification

- Chain No.140
- Chain Pitch (P)44.45mm
- Roller Link Inner Width (W)25.40mm
- Roller Outside Diameter (Dr)25.40mm
- Tooth Width (T)23.5 mm

Sprocket No.		Outer Diameter Do	Pitch Diameter Dp	Shaft Hole Diameter d			Boss Diameter BD	Boss Length BL	Weight kg	Shape	Material	¥	Semi-F
Type	No. of Teeth			Prepared Hole Product	Minimum	Maximum							¥
NK 140B	10	163	143.84	26	27	66	98	56	4.90	Ground Specification	Carbon Structural Steel		
	11	178	157.78	26	27	70	106	56	5.50				
	12	193	171.74	26	27	80	117	56	6.60				
	13	207	185.74	26	27	80	117	63	7.90				
	14	221	199.76	26	27	89	127	63	9.30				
	15	236	213.79	26	27	89	127	63	10.10				
	16	250	227.84	26	27	89	127	63	11.00				
	17	264	241.91	26	27	89	127	63	12.00				
	18	279	255.98	26	27	89	127	63	13.00				
	19	293	270.06	26	27	95	137	71	15.60				
	20	307	284.15	26	27	95	137	71	16.70				
	21	322	298.24	26	27	95	137	71	17.90				
	22	336	312.34	30	31	95	137	71	18.40				
	23	350	326.44	30	31	95	137	71	20.10				
	24	364	340.54	30	31	95	137	71	20.90				
	25	379	354.65	30	31	103	147	80	24.10				
	26	393	368.77	30	31	103	147	80	25.50				
	27	407	382.88	30	31	103	147	80	28.20				
	28	421	397.00	30	31	103	147	80	30.10				
30	450	425.24	30	31	103	147	80	31.50					
32	478	453.49	30	31	103	147	80	36.00					
35	521	495.88	30	31	110	157	90	42.90					
36	535	510.01	30	31	110	157	90	47.40					
38	563	538.27	30	31	110	157	90	51.00					
40	591	566.54	30	31	110	157	90	53.10					
42	620	594.81	30	31	110	157	90	60.00					
NK 140C	45	662	637.22	30	31	118	167	100	68.00	Welded Specification	Common Steel		
	48	705	679.63	30	31	118	167	100	75.00				
	50	733	707.91	30	31	118	167	100	85.30				
	54	790	764.47	35	36	118	167	100	97.40				
	60	875	849.32	35	36	118	167	112	119.30				



Sprocket No. and Quantity



* Goods for which the weight of a single item exceeds 30kg With Sagawa Express/Yamato Transport, products cannot be shipped at any time.



Same-day shipping



* Since we also manufacture sizes other than those in the catalog, and machine shaft holes/keys/taps, etc., depending on your request, please contact our company's sales office for details.

* Please refer to P24 to P33 for the Semi-F Series <Complete Product> order method.