

 
NK160B/NK160C




Standard Sprocket B-type/C-type

Order No. Example

NK160B 20



Ground Specification Welded Specification

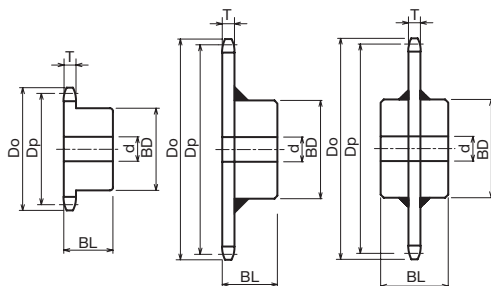

B-Type Ground Specification B-Type Welded Specification C-Type Welded Specification

- Chain No.160
- Chain Pitch (P)50.80mm
- Roller Link Inner Width (W)31.75mm
- Roller Outside Diameter (Dr)28.58mm
- Tooth Width (T)29.4 mm

Sprocket No.		Outer Diameter Do	Pitch Diameter Dp	Shaft Hole Diameter d			Boss Diameter BD	Boss Length BL	Weight kg	Shape	Material	¥	Semi-F ¥
Type	No. of Teeth			Prepared Hole Product	Minimum	Maximum							
NK 160B	10	187	164.39	26	27	70	105	63	6.80	Ground Specification	Carbon Structural Steel		
	11	204	180.31	26	27	80	117	63	8.30				
	12	220	196.28	26	27	89	127	63	9.90				
	13	237	212.27	26	27	95	137	71	12.50				
	14	253	228.30	26	27	95	137	71	13.80				
	15	269	244.33	30	31	95	137	71	15.20				
	16	286	260.39	30	31	103	147	71	17.40				
	17	302	276.46	30	31	103	147	71	18.90				
	18	319	292.55	30	31	103	147	71	20.60				
	19	335	308.64	30	31	103	147	71	22.30				
NK 160C	20	351	324.74	30	31	103	147	71	24.20	Welded Specification	Common Steel		
	21	368	340.84	30	31	103	147	71	26.10				
	22	384	356.96	35	36	118	167	80	30.20				
	24	416	389.19	35	36	118	167	80	34.40				
	25	433	405.32	35	36	118	167	80	36.60				
	26	449	421.45	35	36	118	167	80	38.90				
	30	514	485.99	35	36	118	167	100	52.30				
	32	546	518.28	35	36	118	167	100	59.00				
	35	595	566.71	35	36	118	167	100	66.90				
	40	676	647.47	35	36	118	167	112	88.00				
45	757	728.25	35	36	132	187	125	115.00					
48	806	776.72	35	36	132	187	125	128.00					
50	838	809.04	35	36	132	187	125	138.70					
54	903	873.68	35	36	132	187	125	158.40					
60	1,000	970.65	35	36	132	187	125	190.80					



Sprocket No. and Quantity



* Goods for which the weight of a single item exceeds 30kg
With Sagawa Express/Yamato Transport, products cannot be shipped at any time.



Same-day shipping



* Since we also manufacture sizes other than those in the catalog, and machine shaft holes/keys/taps, etc., depending on your request, please contact our company's sales office for details.

* Please refer to P24 to P33 for the Semi-F Series <Complete Product> order method.