



SUS2040B



SUS Standard Stainless Steel Double Pitch Sprocket for S Rollers B-type

Order No. Example

 SUS 2040B 9 1/2

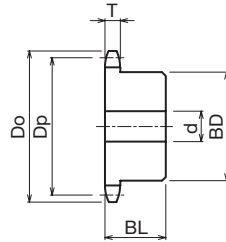

- Chain No.C2040
- Chain Pitch (P)25.4 mm
- Roller Link Inner Width (W) 7.95mm
- Roller Outside Diameter (Dr) 7.92mm
- Tooth Width (T) 7.2 mm

m Stainless Steel **GB** 304

Type	Action No. of Teeth	Actual No. of Teeth	Outer Diameter Do	Pitch Diameter Dp	Shaft Hole Diameter d			Boss Diameter BD	Boss Length BL	Shape	Weight kg	¥	Semi-F ¥
					Prepared Holes	Minimum	Maximum						
SUS 2040B	9 1/2	19	84	78.23	14	15	38	60	25	Ground Specification	0.64		
	10 1/2	21	92	86.17	14	15	46	69	25		0.93		
	11 1/2	23	99	94.15	14	15	51	77	25		0.99		
	12 1/2	25	108	102.14	14	15	42	63	25		1.06		



Sprocket No. and Quantity



Same-day shipping

Postage



Guide

* Since we also manufacture sizes other than those in the catalog, and machine shaft holes/keys/taps, etc., depending on your request, please contact our company's sales office for details.

* Please refer to P24 to P33 for the Semi-F Series <Complete Product> order method.