



SUS2042B



SUS Standard Stainless Steel Double Pitch Sprocket for R Rollers B-type

● Order No. Example

 SUS 2042B 12

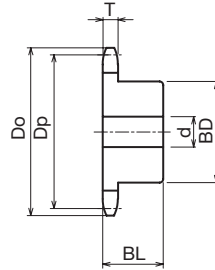

- Chain No.C2042
- Chain Pitch (P)25.4 mm
- Roller Link Inner Width (W) 7.95mm
- Roller Outside Diameter (Dr)15.88mm
- Tooth Width (T) 7.2 mm

m Stainless Steel **GB** 304

| Type | Action No. of Teeth | Outer Diameter Do | Pitch Diameter Dp | Shaft Hole Diameter d | | | Boss Diameter BD | Boss Length BL | Shape | Weight kg | ¥ | Semi-F ¥ |
|------------------|---------------------|-------------------|-------------------|-----------------------|---------|---------|------------------|----------------|----------------------|-----------|---|----------|
| | | | | Prepared Holes | Minimum | Maximum | | | | | | |
| SUS 2042B | 10 | 93 | 82.20 | 15 | 16 | 42 | 63 | 25 | Ground Specification | 0.70 | | |
| | 11 | 102 | 90.16 | 15 | 16 | 42 | 63 | 25 | | 0.77 | | |
| | 12 | 108 | 98.14 | 15 | 16 | 42 | 63 | 25 | | 0.84 | | |
| | 13 | 118 | 106.14 | 16 | 17 | 42 | 63 | 25 | | 0.97 | | |



Order Method

Sprocket No. and Quantity



Postage

Same-day shipping



Guide

* Since we also manufacture sizes other than those in the catalog, and machine shaft holes/keys/taps, etc., depending on your request, please contact our company's sales office for details.

* Please refer to P24 to P33 for the Semi-F Series <Complete Product> order method.