


 
2050B



Standard Double Pitch Sprocket for S Rollers B-type

Order No. Example

2050B 6 1/2

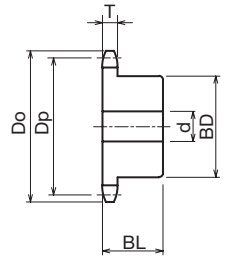

- Chain No.C2050
- Chain Pitch (P)31.75mm
- Roller Link Inner Width (W) 9.53mm
- Roller Outside Diameter (Dr)10.16mm
- Tooth Width (T) 8.7 mm

- m Carbon Structural Steel
- h High-frequency Hardened Teeth

Type	No. of Active Teeth	Actual No. of Teeth	Outer Diameter Do	Pitch Diameter Dp	Shaft Hole Diameter d			Boss Diameter BD	Boss Length BL	Weight kg	¥	Semi-F ¥
					Prepared Holes	Minimum	Maximum					
2050B	6 1/2	13	74	68.32	12	13	25	44	25	0.38		
	7 1/2	15	84	78.06	12	13	32	54	25	0.55		
	8 1/2	17	94	87.89	14	15	45	65	25	0.76		
	9 1/2	19	105	97.78	14	15	48	73	28	1.06		
	10 1/2	21	115	107.72	14	15	48	73	28	1.16		
	11 1/2	23	125	117.68	16	17	48	73	28	1.27		
	12 1/2	25	135	127.67	16	17	48	73	28	1.40		



Sprocket No. and Quantity



Same-day shipping



* Since we also manufacture sizes other than those in the catalog, and machine shaft holes/keys/taps, etc., depending on your request, please contact our company's sales office for details.

* Please refer to P24 to P33 for the Semi-F Series <Complete Product> order method.