



 
2082B



Standard Double Pitch Sprocket for R Rollers B-type

● Order No. Example

2082B 20

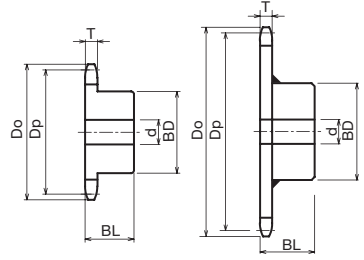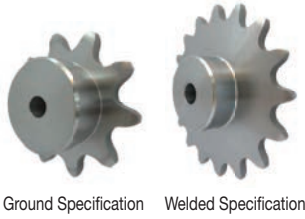

- Chain No.C2082H
- Chain Pitch (P)50.80mm
- Roller Link Inner Width (W)15.88mm
- Roller Outside Diameter (Dr)28.58mm
- Tooth Width (T)14.6 mm

Type	Action No. of Teeth	Outer Diameter Do	Pitch Diameter Dp	Shaft Hole Diameter d			Boss Diameter BD	Boss Length BL	Shape	Material	Weight kg	¥	Semi-F ¥
				Prepared Holes	Minimum	Maximum							
2082B	7	136	117.08	22	23	50	76	40	Ground Specification	Carbon Structural Steel	1.85		
	8	153	132.75	22	23	60	93	40			2.64		
	9	170	148.53	26	27	65	110	40			3.56		
	10	187	164.39	26	27	63	93	40	Welded Specification	Common Steel	3.29		
	11	204	180.31	26	27	75	107	45			4.42		
	12	220	196.28	26	27	75	107	45			4.94		
	13	237	212.27	26	27	75	107	45			5.46		
	14	253	228.29	26	27	75	107	45			6.09		
	15	269	244.33	30	31	75	107	45			6.70		
	16	286	260.39	30	31	75	107	45			7.42		
	17	302	276.46	30	31	75	107	45			8.12		
	18	319	292.55	30	31	80	117	50			9.76		
	19	335	308.64	30	31	80	117	50			10.56		
	20	351	324.74	30	31	80	117	50			11.46		
	24	416	389.19	35	36	80	117	50	16.30				
	25	433	405.32	35	36	80	117	50	17.50				
	26	449	421.45	35	36	80	117	50	18.70				
	28	481	453.72	35	36	80	117	50	21.20				
	30	514	485.99	35	36	80	117	50	24.00				



Sprocket No. and Quantity



Same-day shipping



* Since we also manufacture sizes other than those in the catalog, and machine shaft holes/keys/taps, etc., depending on your request, please contact our company's sales office for details.

* Please refer to P24 to P33 for the Semi-F Series <Complete Product> order method.

Semi-F Series & FITLINK
Roller Chains
Chain Accessories
Idlers & Tensioners
Sprockets
Oilless Bushings
Transmission Accessories
Conveyor Chains/Sprockets
Chain Couplings
Resin Halls
Tight Speed/Center /Transp/Chains
Timing Belts/Pulleys/Ranges
Shaft Collars
Pinions/Racks/Miter Gears
Imperfect Products