


K Standard Pinion Gear <Module 5>



● Order No. Example

M5B20
Pinion Gear No.

M6B20
Pinion Gear No.

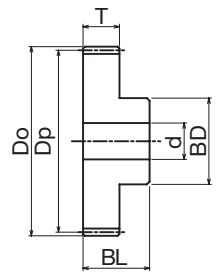

S1 Shape

- m Carbon Structural Steel
- s Black Oxide Finish

<M5>

Pinion Gear No.	No. of Teeth	Tooth Diameter Do	Reference Diameter Dp	Hole Diameter d H7	Boss Diameter BD	Tooth Width T	Total Length BL	Shape	Mass (kg)	¥	Semi-F ¥
M 5 B 12	12	70	60	22	46				1.2		
M 5 B 13	13	75	65	22	50				1.5		
M 5 B 14	14	80	70	22	52	50	75	S1	1.7		
M 5 B 15	15	85	75	22	60				2.0		
M 5 B 16	16	90	80	22	65				2.3		
M 5 B 17	17	95	85	22	68				2.6		
M 5 B 18	18	100	90	22	70				2.9		
M 5 B 19	19	105	95	22	76	50	75	S1	3.5		
M 5 B 20	20	110	100	22	82				3.8		
M 5 B 21	21	115	105	25	90				4.4		
M 5 B 22	22	120	110	25	95				4.8		
M 5 B 23	23	125	115	25	100				5.5		
M 5 B 24	24	130	120	25	100	50	75	S1	5.7		
M 5 B 25	25	135	125	25	105				6.4		
M 5 B 26	26	140	130	25	110				6.6		
M 5 B 27	27	145	135	25	110				7.6		
M 5 B 28	28	150	140	25	110				8.0		
M 5 B 29	29	155	145	25	115	50	75	S1	8.2		
M 5 B 30	30	160	150	25	120				8.8		
M 5 B 32	32	170	160	30	120				9.8		
M 5 B 34	34	180	170	30	120				11.8		
M 5 B 35	35	185	175	30	120				12		
M 5 B 36	36	190	180	30	120	50	71	S1	12		
M 5 B 38	38	200	190	30	120				14		
M 5 B 40	40	210	200	30	120				13		



Pinion Gear No. and Quantity



* Since we also manufacture sizes other than those in the catalog, and machine shaft holes/keys/taps, etc., depending on your request, please contact our company's sales office for details.



Same-day shipping