



EPIC® H-B 16 TG-RO

Housing design H-B. The industry standard.



Info

- Non-slip ridges for comfortable disconnecting

EPIC® H-B 16 TGH-RO

Housing design H-B. The industry standard.




Info

- Non-slip ridges for comfortable disconnecting
- More interior space for wiring

EPIC® H-B 16 TS-RO

Housing design H-B. The industry standard.

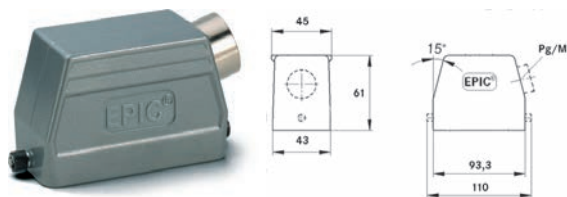

Info

- Non-slip ridges for comfortable disconnecting

Benefits

- The housing standard. Wide choice for all applications

Application range

- Plant engineering
- Light & sound technology
- Plastics industry

Product features

EPIC® H-B 16 TG-RO

- Hood, low version
- Reels for single lever
- Straight cable entry
- Versions with / without neck

EPIC® H-B 16 TGH-RO

- Hood, high version
- Reels for single lever
- Straight cable entry
- Versions with / without neck

EPIC® H-B 16 TS-RO

- Hood, low version
- Reels for single lever
- Side cable entry
- Versions with neck

Suitable inserts

- Refer to Selection Table A10 to select the required inserts and housings

Technical data

ETIM ETIM 5.0 Class-ID: EC000437
ETIM 5.0 Class-Description: Housing for industrial connectors

Material
Housing: powder-coated aluminium alloy, grey
Lever: zinc-plated steel
Sealing: NBR

IP **Protection rating**
IP 65 (latched)

DIN VDE Certified production control:
VDE-REG. no.: B437
UL-tested:
UL File Number: E75770

Temperature range
-40°C to +100°C,
short-term up to +125°C

Article number	Article description	M	PG	Neck	Pieces / PU
H-B housing: hood (straight cable entry, bolts for single lever)					
10080900	H-B 16 TG-RO 21		21	yes	5
19080900	H-B 16 TG-RO M25	25			5
H-B housing: hood (straight cable entry, bolts for single lever, high version)					
70094200	H-B 16 TGH-RO 21		21	yes	5
70094400	H-B 16 TGH-RO 29		29	yes	5
79094200	H-B 16 TGH-RO M25	25			5
79094400	H-B 16 TGH-RO M32	32			5
79094600	H-B 16 TGH-RO M40	40			5
H-B housing: hood (side cable entry, bolts for single lever)					
10082900	H-B 16 TS-RO 21		21	yes	5
10092900	H-B 16 TS-RO 29		29	yes	5
19082900	H-B 16 TS-RO M25	25		yes	5
19092900	H-B 16 TS-RO M32	32		yes	5

Photographs are not to scale and do not represent detailed images of the respective products.

Accessories

- SKINTOP® MS-M
- SKINTOP® for industrial connectors
- Easy to install