



EPIC® H-B 24 TGB

Housing design H-B. The industry standard.



Info

- Non-slip ridges for comfortable disconnecting
- Double lever version with 2 levers for increased safety
- For connection with counterpart with integrated cover

EPIC® H-B 24 TGBH

Housing design H-B. The industry standard.




Info

- Non-slip ridges for comfortable disconnecting
- For connection with counterpart with integrated cover
- More interior space for wiring

EPIC® H-B 24 TS

Housing design H-B. The industry standard.

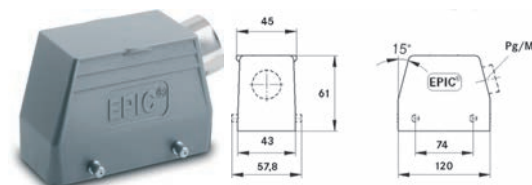

Info

- Non-slip ridges for comfortable disconnecting

Benefits

- Ideal for many applications due to a wide range of housings and inserts

Application range

- Plant engineering
- Light & sound technology
- Plastics industry

Product features

EPIC® H-B 24 TGB

- Hood, low version
- Dual levers
- Straight cable entry
- Versions with / without neck

EPIC® H-B 24 TGBH

- Hood, high version
- Dual levers
- Straight cable entry
- Versions with / without neck

EPIC® H-B 24 TS

- Hood, low version
- Bolts for double lever
- Side cable entry
- Versions with neck

Suitable inserts

- Refer to Selection Table A10 to select the required inserts and housings

Technical data

ETIM ETIM 5.0 Class-ID: EC000437
ETIM 5.0 Class-Description: Housing for industrial connectors

Material
Housing: powder-coated aluminium alloy, grey
Lever: zinc-plated steel
Sealing: NBR

IP **Protection rating**
IP 65 (latched)

DIN VDE Certified production control:
VDE-REG. no.: B437
UL-tested:
UL File Number: E75770

Temperature range
-40°C to +100°C,
short-term up to +125°C

Article number	Article description	M	PG	Neck	Pieces / PU
H-B housing: hood (straight cable entry, double lever)					
10122000	H-B 24 TGB 21		21	yes	5
10112000	H-B 24 TGB 29		29	yes	5
19122000	H-B 24 TGB M25	25			5
19112000	H-B 24 TGB M32	32			5
H-B housing: hood (straight cable entry, double lever, high version)					
70155400	H-B 24 TGBH 21		21	yes	5
70155600	H-B 24 TGBH 29		29	yes	5
79155400	H-B 24 TGBH M25	25			5
79155600	H-B 24 TGBH M32	32			5
H-B housing: hood (side cable entry, bolts for double lever)					
10113000	H-B 24 TS 21		21	yes	5
10123000	H-B 24 TS 29		29	yes	5
19113000	H-B 24 TS M25	25		yes	5
19123000	H-B 24 TS M32	32		yes	5

Photographs are not to scale and do not represent detailed images of the respective products.

Accessories

- SKINTOP® MS-M
- SKINTOP® for industrial connectors
- Easy to install