


## SILVYN® KLICK-S / SILVYN® KLICK-D / SILVYN® KLICK-V

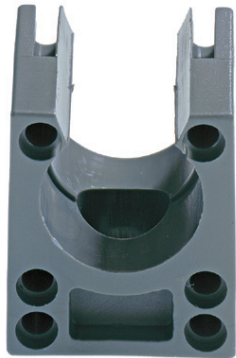

SILVYN® KLICK-S



SILVYN® KLICK-D



SILVYN® KLICK-V

### Benefits

#### SILVYN® KLICK-S

- Fast assembly
- Easy to disassemble
- High tensile strength
- Conduit retained by rib

#### SILVYN® KLICK-D

- Ensures that the conduit is fixed to the conduit-holder

#### SILVYN® KLICK-V

- Connects several conduit holders with one another

### Application range

#### SILVYN® KLICK-S

- In combination with protective conduit
- SILVYN® RILL PA6
- SILVYN® RILL PA12
- Fastening of conduits on machine walls for all applications

#### SILVYN® KLICK-D

- In combination with
- SILVYN® KLICK S
- Cover for conduit holder SILVYN® KLICK S

#### SILVYN® KLICK-V

- In combination with
- SILVYN® KLICK S

### Product features

#### SILVYN® KLICK-S

- Impact-resistant polyamide

#### SILVYN® KLICK-D

- Fits tightly to SILVYN® KLICK S

#### SILVYN® KLICK-V

- Fits tightly to SILVYN® KLICK S

### Product Make-up

#### SILVYN® KLICK-S

- Multi-part conduit holder with M5 borehole for fixation

#### SILVYN® KLICK-D

- Cover with connection pins

#### SILVYN® KLICK-V

- Connection pin

### Suitable conduits

- SILVYN® RILL PA 6 Page 862

### Technical data



ETIM 5.0 Class-ID: EC001171  
ETIM 5.0 Class-Description:  
Holder for protective hose



#### Colour delivered

Grey (RAL 7001)  
Black (RAL 9005), UV-resistant



#### Material

PA6



#### Temperature range

SILVYN® KLICK-S

-30 °C to +70 °C

SILVYN® KLICK-D

-40 °C to +115 °C

SILVYN® KLICK-V

-40 °C to +115 °C

Article number	Nominal size	For conduit with outer Ø (mm)	Pieces / PU
<b>SILVYN® KLICK-S grey</b>			
61811110	10	10	100
61811120	13	13	100
61811130	16	15.8	50
61811190	18	18.5	50
61811140	21	21.2	50
61811150	28	28.5	50
61811160	34	34.5	30
61811170	42	42.5	20
61811180	54	54.5	20
<b>SILVYN® KLICK-D grey</b>			
61811200	10/13		100
61811260	16		50
61811210	21		50
61811220	28		50
61811230	34		30
61811240	42		20
61811250	54		20
<b>SILVYN® KLICK-D black</b>			
61811205	13		100
61811265	16		50
61811215	21		50
61811225	28		50
61811235	34		30
61811245	42		20
61811255	54		20
<b>SILVYN® KLICK-V grey</b>			
61811270			100
<b>SILVYN® KLICK-V black</b>			
61811275			100

Photographs are not to scale and do not represent detailed images of the respective products.