
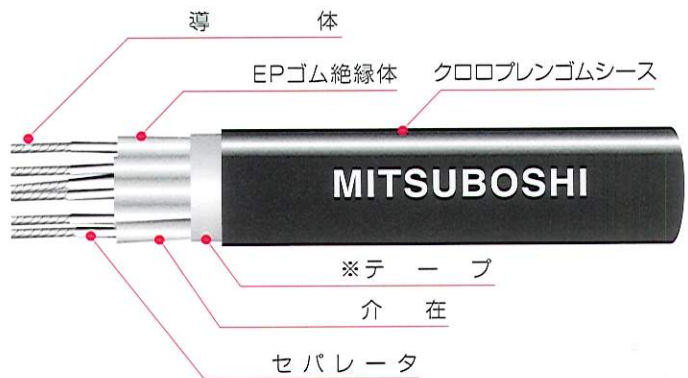
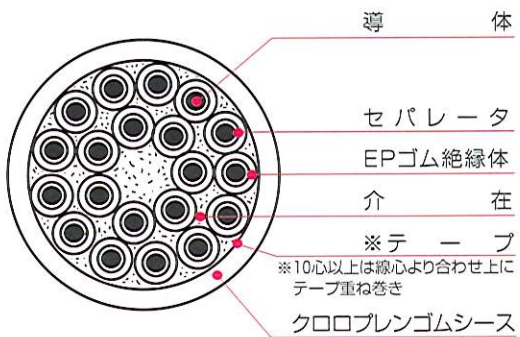


# 600Vゴムキャブタイヤケーブル

## 構造

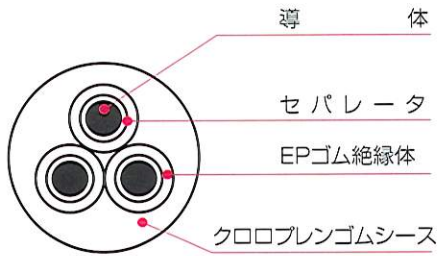

## 質量表

公称断面積 mm <sup>2</sup>	概算質量 kg/km																		
	単 心	2 心	3 心	4 心	5 心	6 心	7 心	8 心	9 心	10 心	12 心	13 心	14 心	15 心	16 心	18 心	20 心	30 心	
0.75	45	105	120	150	175	215	240	275	315	330	335	360	375	410	425	475	520	730	
1.25	55	130	155	185	225	270	310	360	410	435	450	480	510	545	570	635	695	980	
2	65	160	185	230	275	340	395	440	510	540	565	605	635	685	720	805	895	1265	
3.5	90	225	270	340	415	500	580	660	745	800	845						1350		
5.5	125	325	390	495	600	730	850	975	1115	1190	1260								
8	155	405	495	625	790	945	1095												
14	230	595	750	955	1205	1395													
22	370	1010	1270	1585	2045	2360													
(30)	470	1265	1600	2010	2605	3100													
38	565	1535	1940	2445	3165	3650													
(50)	710	1965	2490	3135															
60	855	2355	2985	3780															
(80)	1160	3250	4105	5190															
100	1410	3935	5015	6345															
(125)	1680	4675	5980																
150	1915	5420	6890																
200	2600																		
250	3125																		
325	3975																		