


## ■VGフランジ



### ◆寸法

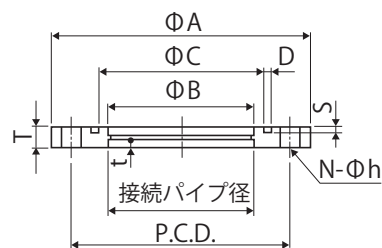

■材質…SUS304


(単位: mm)

コード	接続パイプ	ΦA	ΦB	ΦC	D	S	T	t	N (箇所)	Φh
MCJ-2010	10A(Φ17.3)	70	18	24	5	3.0	8	3	4	10
MCJ-2020	20A(Φ27.2)	80	28	34	5	3.0	8	3	4	10
MCJ-2025	25A(Φ34.0)	90	35	40	5	3.0	8	3	4	10
MCJ-2040	40A(Φ48.6)	105	50	55	5	3.0	10	3	4	10
MCJ-2050	50A(Φ60.5)	120	62	70	5	3.0	10	3	4	10
MCJ-2065	65A(Φ76.3)	145	77	85	5	3.0	10	3	4	12
MCJ-2080	80A(Φ89.1)	160	90	100	5	3.0	12	5	4	12
MCJ-2100	100A(Φ114.3)	185	115	120	5	3.0	12	5	8	12
MCJ-2125	125A(Φ139.8)	210	141	150	5	3.0	12	5	8	12
MCJ-2150	150A(Φ165.2)	235	166	175	5	3.0	12	5	8	12
MCJ-2200	200A(Φ216.3)	300	217	225	8	4.5	16	8	8	15
MCJ-2250	250A(Φ267.4)	350	268	275	8	4.5	16	8	12	15

## ■ニップル



### ◆寸法

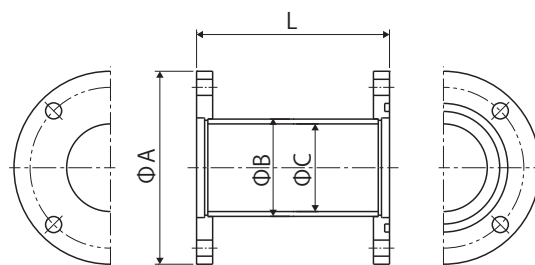

■パイプ・フランジ…SUS304

■表面処理…G.B.B.

(単位: mm)

コード	フランジ	ΦA	ΦB	ΦC	L
MVIJ-020	VG/VF 20	80	27.2	23.0	100
MVIJ-025	VG/VF 25	90	34.0	28.4	110
MVIJ-040	VG/VF 40	105	48.6	43.0	120
MVIJ-050	VG/VF 50	120	60.5	54.9	120
MVIJ-080	VG/VF 80	160	89.1	83.1	220
MVIJ-100	VG/VF100	185	114.3	108.3	240
MVIJ-125	VG/VF125	210	139.8	133.0	300
MVIJ-150	VG/VF150	235	165.2	158.4	300
MVIJ-200	VG/VF200	300	216.3	208.3	300
MVIJ-250	VG/VF250	350	267.4	259.4	300