


Uボルト用楕円プレート

Oval Plate For U-Bolt

材質：ステンレス SUS304


(価格改定日 H20.1) (mm)

品番	L1	L2	W	d	t	適用Uボルト	weight (g)	価格(円)/個	入数	コード No.
UBP-0430	40	30	10	4.7	1	UB-4	2	90	100	2322
UBP-0535	47	35	12	5.4	1	UB-5	4	100	100	2323
UBP-0635	50	35	15	6.5	1.5	UB-6	7	110	100	2324
UBP-0832	48	32	16	8.8	1.5	UC-80932	7	160	100	2325
UBP-0834	51	34	16	8.8	1.5	U-80634	7	160	100	2326
UBP-0835	51	35	16	8.8	1.5	UB-8, U-80835 U-81035, U-81135	7	170	100	2327
UBP-0840	56	40	16	8.8	1.5	U-81040	8	180	100	2328
UBP-0850	66	50	16	8.8	1.5	U-80850	10	200	100	2329
UBP-1050	70	50	20	11	2.0	UB-10	17	220	50	2330
UBP-1260	84	60	24	12.8	2.5	UB-12	31	330	50	2331

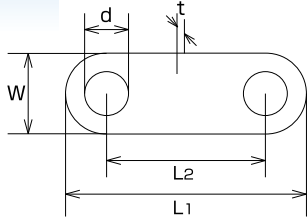

一般鋼管用Uボルト

General Plumbing U-Bolt

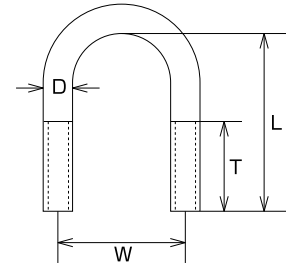

材質：ステンレス SUS304

(価格改定日 H20.1) (mm)

品番	D	L	T	W	捻径	weight (g)	価格(円)/個
UK-6M8A	5.3	27	15	21	M-6	13	125
UK-6M10A	5.3	33	18	25	M-6	15	132
UK-6M15A	5.3	36	18	29.5	M-6	17	140
UK-6M20A	5.3	42	18	34	M-6	19	158
UK-6M25A	5.3	49	25	41	M-6	22	174
UK-6M32A	5.3	57	25	50.5	M-6	26	215
UK-6M40A	5.3	68	25	57	M-6	30	240
UK-6M50A	5.3	80	30	70	M-6	36	264
UK-8M10A	7.1	38	24	27	M-8	31	236
UK-8M15A	7.1	42	24	31	M-8	34	264
UK-8M20A	7.1	48	24	37	M-8	39	280
UK-8M25A	7.1	54	25	44	M-8	44	297
UK-8M32A	7.1	62	30	52	M-8	51	330
UK-8M40A	7.1	67	30	59	M-8	55	363
UK-8M50A	7.1	80	30	72	M-8	66	429
UK-8M65A	7.1	96	30	86	M-8	78	570
UK-10M10A	8.9	43	28	28	M-10	54	380
UK-10M15A	8.9	46	30	34	M-10	60	413
UK-10M20A	8.9	51	30	40	M-10	66	429
UK-10M25A	8.9	59	30	46	M-10	76	495

材質：ステンレス SUS304

(価格改定日 H20.1) (mm)

品番	D	L	T	W	捻径	weight (g)	価格(円)/個
UK-10M32A	8.9	68	30	56	M-10	86	560
UK-10M40A	8.9	74	30	62	M-10	95	594
UK-10M50A	8.9	85	30	74	M-10	108	660
UK-10M65A	8.9	107	35	88	M-10	135	792
UK-10M80A	8.9	117	35	101	M-10	147	908
UK-10M100A	8.9	145	35	126	M-10	183	1,130
UK-12M65A	10.72	107	45	90	M-12	197	1,360
UK-12M80A	10.72	119	45	103	M-12	225	1,400
UK-12M90A	10.72	131	45	116	M-12	243	1,630
UK-12M100A	10.72	150	45	129	M-12	274	1,770
UK-12M125A	10.72	175	45	154	M-12	318	2,020
UK-12M150A	10.72	200	45	182	M-12	373	2,310
UK-12M200A	10.72	252	45	232	M-12	462	3,060
UK-12M250A	10.72	307	50	282	M-12	561	4,200
UK-16M100A	14.5	151	60	134	M-16	511	4,290
UK-16M125A	14.5	175	60	160	M-16	597	4,420
UK-16M150A	14.5	202	60	186	M-16	679	4,600
UK-16M200A	14.5	254	60	236	M-16	859	5,700
UK-16M250A	14.5	308	60	286	M-16	1036	6,700
UK-16M300A	14.5	368	70	341	M-16	1234	7,740

※上記以外のサイズも製造可能です。ご照会下さい。

※ナットは別売です。