




角頭シャックル

Square Head Pin type D-Shackle

材質：ステンレス SUS304

(価格改定日 H20.1) (mm)

品番	D	L	B	d	捻径	weight (g)	参考使用荷重 (kgf) (kN)		価格(円)/個	入数	コード No.
QS-4	4	16	8	8	M-4	7	50	0.49	420	20	666
QS-5	5	20	10	10	M-5	13	90	0.88	500	20	571
QS-6	6	24	12	12	M-6	24	170	1.67	530	20	572
QS-7	7	28	14	14	W-5/16	39	200	1.96	660	20	230
QS-8	8	32	17	16	W-5/16	57	250	2.45	740	20	231
QS-9	9	36	18	18	W-3/8	78	300	2.94	800	20	232
QS-10	10	40	20	20	W-3/8	115	350	3.43	1,100	10	233
QS-12	12	48	24	24	W-1/2	190	420	4.12	1,380	10	234
QS-13	13	52	26	26	W-1/2	240	500	4.90	1,630	10	235
QS-16	16	64	32	32	W-5/8	460	800	7.84	3,300	5	236
QS-19	19	76	38	38	W-3/4	755	1000	9.80	6,000	5	237
QS-22	22	85	44	47	W-7/8	1250	1500	14.70	9,100	5	1125
QS-25	25	100	50	50	W-1	1630	2000	19.60	13,300	5	1283

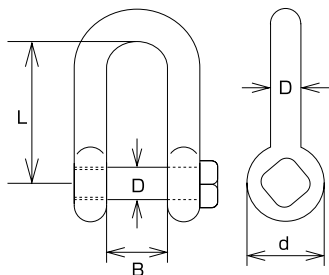

SBMシャックル


Safety D-shackle, Bolt. type




材質：ステンレス SUS304・SUS316

(価格改定日 H20.1) (mm)

品番	D	L	B	d	t	捻径	weight (g)	参考使用荷重 (kgf) (kN)		SUS304		SUS316		入数
										価格(円)/個	コードNo.	価格(円)/個	コードNo.	
SBM-6	6	24	12	12	6	M-6	29	180	1.76	2,000	737	3,000	1595	20
SBM-7	8	28	14	14	7	M-8	51	250	2.45	2,200	738	3,300	1596	20
SBM-8	8	32	16	16	8	M-8	72	300	2.94	2,500	739	3,750	1597	10
SBM-9	10	36	18	18	9	M-10	110	400	3.92	2,900	740	4,350	1598	10
SBM-10	10	40	20	20	10	M-10	135	600	5.88	3,500	273	5,250	1599	10
SBM-12	12	48	24	24	12	M-12	230	750	7.35	4,100	741	6,150	1600	10
SBM-13	14	52	26	26	13	M-14	310	900	8.82	4,500	274	6,750	1601	10
SBM-16	16	64	32	32	16	M-16	528	1500	14.70	7,500	275	11,250	1602	5
SBM-19	20	76	38	38	19	M-20	994	2000	19.60	12,800	276	19,200	1603	5
SBM-22	22	88	44	44	22	M-22	1350	2500	24.50	16,800	277	25,200	1604	5
SBM-25	25	100	50	50	25	M-24	1930	3200	31.36	26,200	694	39,300	1605	5
SBM-28	28	112	56	60	28	M-30	3040	4000	39.20	40,700	2093	61,050	2095	1
SBM-32	35	134	64	72	32	M-36	5040	5000	49.00	64,900	2094	97,350	2096	1

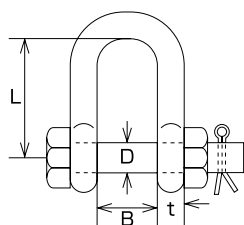

※ナット・フリピン付

 

※SUS316製も在庫がございます。ご注文の際には、品番の前か後に「SUS316」とご指定下さい。



引張試験機 30トン 10トン 2トン用



蛍光X線分析装置



倒立型金属顕微鏡

価格には消費税は含まれておりません。