

With wooden base

RoHS Compliant

ERON®

No.E-412


# Clamping Kits

**Material** S45C and S45C sintered alloy

**Heat Treatment** Heat treatment

**Surface Treatment** Blackened

## Kit Contents

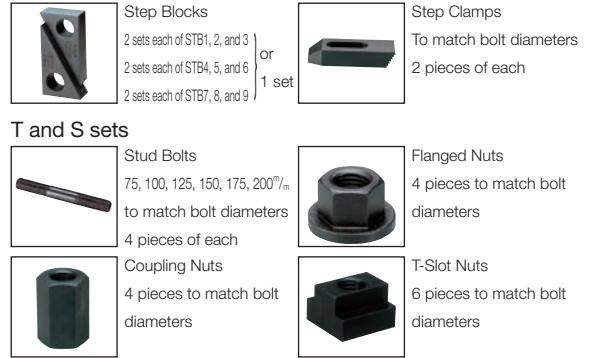

## Specifications

Order No.	No.	Compatible T-slot Width	Screw Diameter (Coarse Thread)	T and S sets	Step Clamps (2 Pieces of Each)	Step Blocks (2 Sets of Each)	Weight (kg)
01050	CMM0108	10	M8×1.25	1 set	STC0101/STC0102/STC0103	STB-1/STB-2/STB-3	7.5
01051	CMM1210	12	M10×1.5	1 set	STC0201/STC0202/STC0203	STB-1/STB-2/STB-3	8.1
01052	CMM1410	14	M10×1.5	1 set	STC0201/STC0202/STC0203	STB-1/STB-2/STB-3	10.1
01053	CMM1412	14	M12×1.75	1 set	STC0301/STC0302/STC0303	STB-1/STB-2/STB-3	10.5
01054	CMM1612	16	M12×1.75	1 set	STC0301/STC0302/STC0303	STB-1/STB-2/STB-3	11.0
01055	CMM1614	16	M14×2	1 set	STC0401/STC0402/STC0403	STB-1/STB-2/STB-3	12.5
01056	CMM1814	18	M14×2	1 set	STC0401/STC0402/STC0403	STB-1/STB-2/STB-3	15.5
01057	CMM1816	18	M16×2	1 set	STC0401/STC0402/STC0403	STB-1/STB-2/STB-3	19.5
01058	CMG1612	16	M12×1.75	1 set	STC0301/STC0302/STC0303	STB-4/STB-5/STB-6	22.0
01059	CMG1614	16	M14×2	1 set	STC0401/STC0402/STC0403	STB-4/STB-5/STB-6	23.5
01060	CMG1814	18	M14×2	1 set	STC0401/STC0402/STC0403	STB-4/STB-5/STB-6	24.0
01061	CMG1816	18	M16×2	1 set	STC0401/STC0402/STC0403	STB-4/STB-5/STB-6	24.5
01062	CMG2016	20	M16×2	1 set	STC0401/STC0402/STC0403	STB-4/STB-5/STB-6	24.5
01063	CMG2018	20	M18×2.5	1 set	STC0501/STC0502/STC0503	STB-4/STB-5/STB-6	25.0
01064	CMG2218	22	M18×2.5	1 set	STC0501/STC0502/STC0503	STB-4/STB-5/STB-6	25.0
01065	CMG2220	22	M20×2.5	1 set	STC0501/STC0502/STC0503	STB-4/STB-5/STB-6	27.0
01066	CMG2418	24	M18×2.5	1 set	STC0501/STC0502/STC0503	STB-4/STB-5/STB-6	25.0
01067	CMG2420	24	M20×2.5	1 set	STC0501/STC0502/STC0503	STB-4/STB-5/STB-6	32.0
01068	CMG2620	26	M20×2.5	1 set	STC0501/STC0502/STC0503	STB-4/STB-5/STB-6	37.0
01069	CMH2622	26	M22×2.5	1 set	STC0601/STC0602/STC0603	STB-7/STB-8/STB-9	43.0
01070	CMH2822	28	M22×2.5	1 set	STC0601/STC0602/STC0603	STB-7/STB-8/STB-9	42.0
01071	CMH2824	28	M24×3	1 set	STC0701/STC0702/STC0703	STB-7/STB-8/STB-9	44.0

## Usage Examples

