


NK-7400

Universal Bellows Type

Flange Standard: JIS,ANSI,DIN

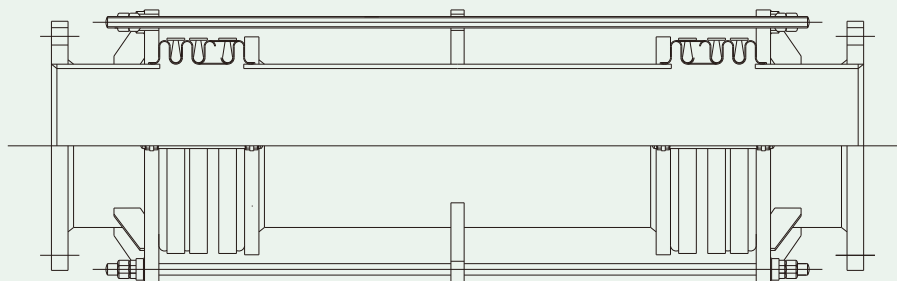

DN	Length(mm)					
	Y=50	Y=100	Y=150	Y=200	Y=250	Y=300
50mm	600	800	1000	1100	1200	1400
65mm	650	850	1000	1200	1400	1600
80mm	750	1000	1300	1400	1700	1800
100mm	850	1100	1300	1500	1700	1800
125mm	750	1000	1200	1300	1500	1600
150mm	800	1050	1350	1450	1600	1800
200mm	900	1200	1400	1700	1800	2050
250mm	1000	1300	1500	1700	1800	2100
300mm	1050	1400	1600	1800	2000	2300
350mm	1100	1500	1700	1900	2150	2450
400mm	1200	1600	1900	2100	2400	2700
450mm	1250	1700	2000	2200	2500	2900
500mm	1400	1800	2100	2400	2700	3100
550mm	1200	1600	1850	2000	2300	2600
600mm	1300	1700	1900	2100	2400	2700

① Bellows	Stainless Steel
② End Pipe	Carbon Steel, Stainless Steel
③ Flange	Carbon Steel, Stainless Steel
④ Reinforcing Ring	Carbon Steel, Stainless Steel
⑤ Guide Flange	Carbon Steel, Stainless Steel
⑥ Neck Ring	Carbon Steel, Stainless Steel
⑦ Common Connector	Carbon Steel, Stainless Steel
⑧ Tie Rods	Carbon Steel, Stainless Steel
⑨ Set Bolt	Carbon Steel, Stainless Steel
⑩ Beam	Carbon Steel, Stainless Steel