



製品型式・寸法表

プラグ LE型 (ホース取り付け用)

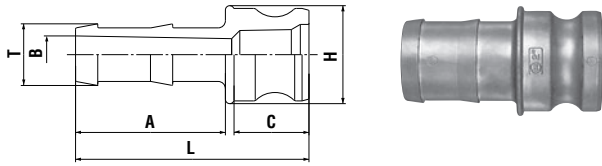


材質	製品型式	サイズ	質量 (g)	寸法 (mm)					
				L	A	C	φH	φT	φB
アルミ 合金/ハ ル	LE-6TPH	3/4"	65	81	52	26	34	21.5	11
	LE-8TPH	1"	100	95	58	34	40	27.5	17.5
	LE-10TPH	1 1/4"	140	102	58	40	48	34	23.5
	LE-12TPH	1 1/2"	190	107	61	42	58	40.5	29.5
	LE-16TPH	2"	290	122	70	48	69	53	40
	LE-20TPH	2 1/2"	390	134.5	80	50	81	67	50
鋼 コ ロ ン	LE-24TPH	3"	545	167	101	61.5	97	79	68
	LE-32TPH	4"	850	176	106	63.5	133	105	93
	LE-6TPH	3/4"	215	90.5	52.5	26	39	21.5	12.5
	LE-8TPH	1"	305	107	60	34.5	41	27.5	20
	LE-10TPH	1 1/4"	440	102	58	40	48	34	25.5
	LE-12TPH	1 1/2"	560	107	61	42	58	40.5	31.5
ステン レス	LE-16TPH	2"	865	131	73	54	70.5	53.5	44.5
	LE-20TPH	2 1/2"	1180	149	84	48	91	67	57
	LE-24TPH	3"	1800	171	104	50	102	79	70
	LE-32TPH	4"	3500	176	109	57	129	105	93
	LE-6TPH	3/4"	170	90	52	35.5	35	21	15
	LE-8TPH	1"	265	107	60	44	42	27	20
ステン レス	LE-10TPH	1 1/4"	430	111	61	40	48	34	25.5
	LE-12TPH	1 1/2"	530	114	61	40	60	40	33
	LE-16TPH	2"	790	131	73	45	70	53	44
	LE-20TPH	2 1/2"	1195	137	80.5	50.5	83	67	56
	LE-24TPH	3"	1755	162	99.5	56.5	102	78	68
	LE-32TPH	4"	2595	174	109	59	130	105	94

プラグ LA型 (おねじ取り付け用)

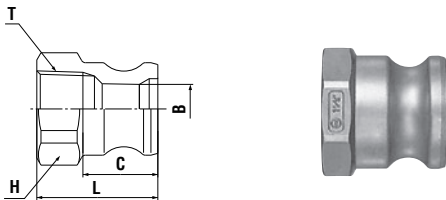


材質	製品型式	サイズ	質量 (g)	寸法 (mm)				
				L	C	H	φB	T
アルミ 合金/ハ ル	LA-6TPF	3/4"	45	42	26	六角36	17	Rc 3/4
	LA-8TPF	1"	65	52	34	六角41	22.5	Rc 1
	LA-10TPF	1 1/4"	110	59	40	六角50	27.5	Rc 1 1/4
	LA-12TPF	1 1/2"	130	58	42	六角60	34.5	Rc 1 1/2
	LA-16TPF	2"	170	63.5	48	八角70	44.5	Rc 2
	LA-20TPF	2 1/2"	320	85	50	八角85	55.5	Rc 2 1/2
鋼 コ ロ ン	LA-24TPF	3"	370	79	52.5	十二角99	73.5	Rc 3
	LA-32TPF	4"	640	82	54	十二角130	100	Rc 4
	LA-6TPF	3/4"	145	42	27	八角34	20	Rc 3/4
	LA-8TPF	1"	190	46	32	八角41	24	Rc 1
	LA-10TPF	1 1/4"	390	59	40	六角50	28	Rc 1 1/4
	LA-12TPF	1 1/2"	420	58	42	六角60	36	Rc 1 1/2
ステン レス	LA-16TPF	2"	560	63.5	48	八角70	45	Rc 2
	LA-20TPF	2 1/2"	950	79	50	八角84	56	Rc 2 1/2
	LA-24TPF	3"	1210	71	50	十二角101	70	Rc 3
	LA-32TPF	4"	1620	79	53	十二角127	101	Rc 4
	LA-6TPF	3/4"	120	39	27	八角33	19	Rc 3/4
	LA-8TPF	1"	170	47	33	八角41	24	Rc 1
ステン レス	LA-10TPF	1 1/4"	270	53.5	41	八角50	28	Rc 1 1/4
	LA-12TPF	1 1/2"	375	55	40	八角58	35.5	Rc 1 1/2
	LA-16TPF	2"	505	62	47	八角69	45	Rc 2
	LA-20TPF	2 1/2"	825	77	49	十二角83	56	Rc 2 1/2
	LA-24TPF	3"	875	72	51	十二角96	73	Rc 3
	LA-32TPF	4"	1470	79	53	十二角124	100	Rc 4

ソケット LC型 (ホース取り付け用) アルミ合金と鋼合金のLC-6TSH型はリングなし

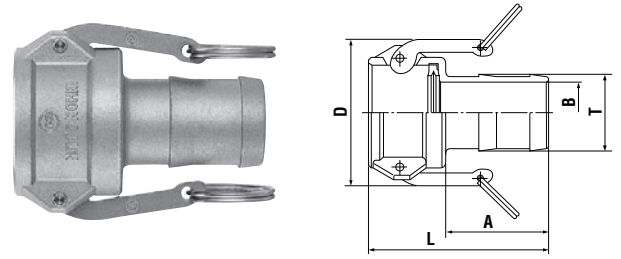

材質	製品型式	サイズ	質量 (g)	寸法 (mm)				
				L	A	D	φT	φB
アルミ 合金/ハ ル	LC-6TSH	3/4"	140	85	52	(60.5)	21.5	11
	LC-8TSH	1"	190	99	58	(61)	27.5	17
	LC-10TSH	1 1/4"	320	104	58	(82)	34	23
	LC-12TSH	1 1/2"	350	108.5	61	(90)	40.5	29
	LC-16TSH	2"	430	122.5	70	(100)	53	41.5
	LC-20TSH	2 1/2"	560	136.5	80	(112)	66.5	54
鋼 コ ロ ン	LC-24TSH	3"	915	175	100	(139)	79	68
	LC-32TSH	4"	1190	180	104	(165)	104	93
	LC-6TSH	3/4"	320	85	52	(61.5)	21.5	13
	LC-8TSH	1"	420	99	58	(61)	27.5	19.5
	LC-10TSH	1 1/4"	700	104	58	(82)	34	25.5
	LC-12TSH	1 1/2"	720	110	62	(91)	41	33
ステン レス	LC-16TSH	2"	870	121	70	(100)	53	44
	LC-20TSH	2 1/2"	1530	137	83	(113)	67	57
	LC-24TSH	3"	1795	160	105	(139)	79	68
	LC-32TSH	4"	3100	163	107	(168)	104	92
	LC-6TSH	3/4"	230	86	52	(55)	21	15
	LC-8TSH	1"	340	99	60	(63)	27	20
ステン レス	LC-10TSH	1 1/4"	615	107	61	(85)	34	25.5
	LC-12TSH	1 1/2"	645	108	61	(91)	40	33
	LC-16TSH	2"	1000	129	73	(101)	53	44
	LC-20TSH	2 1/2"	1270	134	81	(113)	67	57
	LC-24TSH	3"	2065	158	100	(139)	79	67
	LC-32TSH	4"	3020	165	107	(167)	105	94

ソケット LD型 (おねじ取り付け用) アルミ合金と鋼合金のLC-6TSF型はリングなし

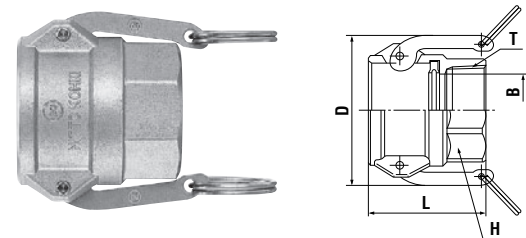

材質	製品型式	サイズ	質量 (g)	寸法 (mm)				
				L	D	H	φB	T
アルミ 合金/ハ ル	LD-6TSF	3/4"	130	53	(60.5)	六角36	21	Rc 3/4
	LD-8TSF	1"	190	64.5	(61)	六角41	26	Rc 1
	LD-10TSF	1 1/4"	330	72.5	(82)	六角50	34	Rc 1 1/4
	LD-12TSF	1 1/2"	360	70.5	(90)	六角60	39	Rc 1 1/2
	LD-16TSF	2"	420	79.5	(100)	八角70	49	Rc 2
	LD-20TSF	2 1/2"	550	88.5	(112)	八角85	59	Rc 2 1/2
鋼 コ ロ ン	LD-24TSF	3"	800	89	(140)	十二角99	75	Rc 3
	LD-32TSF	4"	1140	93	(165)	十二角131	94	Rc 4
	LD-6TSF	3/4"	310	53	(60.5)	六角36	21	Rc 3/4
	LD-8TSF	1"	430	64.5	(61)	六角41	26	Rc 1
	LD-10TSF	1 1/4"	730	72.5	(82)	六角50	34	Rc 1 1/4
	LD-12TSF	1 1/2"	770	70.5	(90)	八角60	39	Rc 1 1/2
ステン レス	LD-16TSF	2"	990	79.5	(100)	八角70	49	Rc 2
	LD-20TSF	2 1/2"	1290	81.5	(113)	八角84	61	Rc 2 1/2
	LD-24TSF	3"	1560	88	(139)	十二角98	76	Rc 3
	LD-32TSF	4"	3590	91	(165)	八角126	96	Rc 4
	LD-6TSF	3/4"	225	52	(55)	八角32	19	Rc 3/4
	LD-8TSF	1"	350	60	(63)	八角41	24	Rc 1
ステン レス	LD-10TSF	1 1/4"	600	68	(85)	八角50	30	Rc 1 1/4
	LD-12TSF	1 1/2"	715	72	(87)	八角58	37.5	Rc 1 1/2
	LD-16TSF	2"	940	78.5	(100)	八角69	50	Rc 2
	LD-20TSF	2 1/2"	1050	82	(113)	十二角83	61	Rc 2 1/2
	LD-24TSF	3"	1605	88	(139)	十二角96	75	Rc 3
	LD-32TSF	4"	2575	94	(167)	十二角125	97	Rc 4