

MSE230SS



Size $\phi 0.1 \sim \phi 6$



MUGEN COATING 2-Flute Super Short End Mill

Total 61 sizes

L/D=1. High rigidity with short length of cut.
Suitable for slotting process

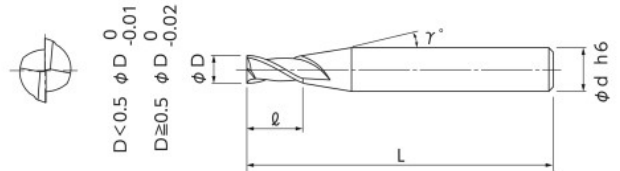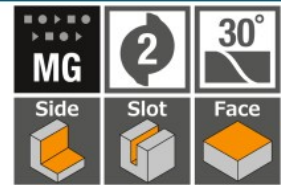

Unit : mm

Code No.	Dia. (D)	Length of Cut (L)	Neck Taper Angle (γ)	Shank Dia. (d)	Overall Length (L)
08-00103-00010	0.1	0.1	9°	4	45
08-00103-00015	0.15	0.15	9°	4	45
08-00103-00020	0.2	0.2	9°	4	45
08-00103-00030	0.3	0.3	9°	4	45
08-00103-00040	0.4	0.4	9°	4	45
08-00103-00050	0.5	0.5	9°	4	45
08-00103-00060	0.6	0.6	9°	4	45
08-00103-00070	0.7	0.7	9°	4	45
08-00103-00080	0.8	0.8	9°	4	45
08-00103-00090	0.9	0.9	9°	4	45
08-00103-00100	1	1	9°	4	45
08-00103-00110	1.1	1.1	9°	4	45
08-00103-00120	1.2	1.2	9°	4	45
08-00103-00130	1.3	1.3	9°	4	45
08-00103-00140	1.4	1.4	9°	4	45
08-00103-00150	1.5	1.5	9°	4	45
08-00103-00160	1.6	1.6	9°	4	45
08-00103-00170	1.7	1.7	9°	4	45
08-00103-00180	1.8	1.8	9°	4	45
08-00103-00190	1.9	1.9	9°	4	45
08-00103-00200	2	2	9°	4	45
08-00103-00210	2.1	2.1	9°	4	45
08-00103-00220	2.2	2.2	9°	4	45
08-00103-00230	2.3	2.3	9°	4	45
08-00103-00240	2.4	2.4	9°	4	45
08-00103-00250	2.5	2.5	9°	4	45
08-00103-00260	2.6	2.6	9°	4	45
08-00103-00270	2.7	2.7	9°	4	45
08-00103-00280	2.8	2.8	9°	4	45
08-00103-00290	2.9	2.9	9°	6	50
08-00103-00300	3	3	9°	6	50

Code No.	Dia. (D)	Length of Cut (L)	Neck Taper Angle (γ)	Shank Dia. (d)	Overall Length (L)
08-00103-00310	3.1	3.1	9°	6	50
08-00103-00320	3.2	3.2	9°	6	50
08-00103-00330	3.3	3.3	9°	6	50
08-00103-00340	3.4	3.4	9°	6	50
08-00103-00350	3.5	3.5	9°	6	50
08-00103-00360	3.6	3.6	9°	6	50
08-00103-00370	3.7	3.7	9°	6	50
08-00103-00380	3.8	3.8	9°	6	50
08-00103-00390	3.9	3.9	9°	6	50
08-00103-00400	4	4	9°	6	50
08-00103-00410	4.1	4.1	9°	6	50
08-00103-00420	4.2	4.2	9°	6	50
08-00103-00430	4.3	4.3	9°	6	50
08-00103-00440	4.4	4.4	9°	6	50
08-00103-00450	4.5	4.5	9°	6	55
08-00103-00460	4.6	4.6	9°	6	55
08-00103-00470	4.7	4.7	9°	6	55
08-00103-00480	4.8	4.8	9°	6	55
08-00103-00490	4.9	4.9	9°	6	55
08-00103-00500	5	5	9°	6	55
08-00103-00510	5.1	5.1	9°	6	55
08-00103-00520	5.2	5.2	9°	6	55
08-00103-00530	5.3	5.3	9°	6	55
08-00103-00540	5.4	5.4	9°	6	55
08-00103-00550	5.5	5.5	9°	6	55
08-00103-00560	5.6	5.6	9°	6	55
08-00103-00570	5.7	5.7	9°	6	55
08-00103-00580	5.8	5.8	9°	6	55
08-00103-00590	5.9	5.9	9°	6	55
08-00103-00600	6	6	-	6	55

How to Order

When you order, indicate MSE230SS (D). ※(γ) is reference value.

■ Semi-standard products, please inquire for price and delivery.