
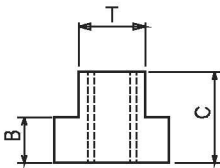


T-スロットナット

T-SLOT NUT

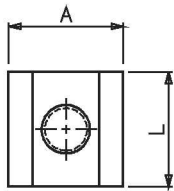

- 材質 S45C
- 硬度 HRC25~30°
- 仕上 黒染

(寸法表) T・S=機械のテーブルスロット幅

No.	T・S	使用ボルト	A	B	C	T	L	質量
1008-TN	10	8	15.8	4.7	12.7	9.5	22	20
1210-TN	12	10	17.5	5.5	12.7	11.7	22	22
1410-TN	14	10	22.2	8.7	15.8	13.8	28	50
1412-TN	14	12	22.2	8.7	15.8	13.8	28	48
1612-TN	16	12	25.4	8.7	15.8	15.8	28	60
1614-TN	16	14	25.4	8.7	15.8	15.8	28	57
1812-TN	18	12	28.5	11.1	19.0	17.5	30	90
1814-TN	18	14	28.5	11.1	19.0	17.5	30	86
1816-TN	18	16	28.5	11.1	19.0	17.5	30	85
2016-TN	20	16	31.7	11.9	19.0	19.7	30	98
2018-TN	20	18	31.7	14.0	25.4	19.7	38	110
2216-TN	22	16	36.0	13.8	25.4	21.7	38	130
2218-TN	22	18	36.0	13.8	25.4	21.7	38	178
2220-TN	22	20	36.0	13.8	25.4	21.7	38	190
2418-TN	24	18	38.2	14.0	25.4	23.5	38	184
2420-TN	24	20	38.2	14.0	25.4	23.5	38	250
2620-TN	26	20	41.3	15.8	25.4	24.7	44	250
2622-TN	26	22	41.3	15.8	25.4	24.7	44	240
2816-TN	28	16	44.0	17.5	28.5	26.9	50	300
2820-TN	28	20	44.0	17.5	28.5	26.9	50	270
2822-TN	28	22	44.0	17.9	28.5	26.9	50	330
2824-TN	28	24	44.0	17.9	28.5	26.9	50	312
3630-TN	36	30	54.0	22.0	44.0	35.5	54	600
4236-TN	42	36	65.0	26.0	52.0	41.5	65	1,000

貫通品



No.	T・S	使用ボルト	A	B	C	T	L	質量
1008-TNK	10	8	15.8	4.7	12.7	9.5	22	20
1210-TNK	12	10	17.5	5.5	11.7	11.7	22	22
1412-TNK	14	12	22.2	8.7	15.8	13.8	28	48
1614-TNK	16	14	25.4	8.7	15.8	15.8	28	57
1814-TNK	18	14	28.5	11.1	19.0	17.5	30	85
1816-TNK	18	16	28.5	11.1	19.0	17.5	30	85
2016-TNK	20	16	31.7	11.9	19.0	19.7	30	98
2218-TNK	22	18	36.0	13.8	25.4	21.7	38	178
2220-TNK	22	20	36.0	13.8	25.4	21.7	38	190
2420-TNK	24	20	38.2	14.0	25.4	23.5	38	250

インチサイズ

No.	T・S	使用ボルト	A	B	C	T	L	質量
1404-TN	9/16	4分	22.2	8.7	15.9	13.9	28.6	48
1604-TN	5/8	4分	25.4	8.7	15.9	15.9	28.6	59
1805-TN	11/16	5分	28.6	11.1	19.1	17.5	31.8	89
2005-TN	3/4	5分	31.8	11.9	19.1	19.1	31.8	98
2006-TN	13/16	6分	31.8	14.3	25.4	19.7	38.1	110
2206-TN	7/8	6分	36.1	13.9	25.9	21.4	38.1	190

回転T-スロットナット

ROTARY T-SLOT NUT

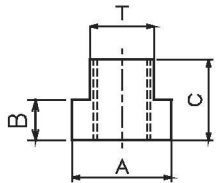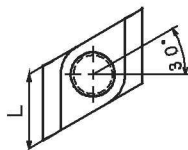


(寸法表)

No.	T・S	使用ボルト	A	B	C	T	L	質量
1208-RTN	12	8	17.5	5.5	12.7	10.8	11.5	10
1210-RTN	12	10	17.5	5.5	12.7	10.8	11.5	10
1410-RTN	14	10	22.2	8.7	15.8	13.8	13.5	23
1412-RTN	14	12	22.2	8.7	15.8	13.8	13.5	23
1612-RTN	16	12	25.4	8.7	15.8	15.8	15.5	30
1614-RTN	16	14	25.4	8.7	15.8	15.8	15.5	30
1814-RTN	18	14	28.5	11.1	19.0	17.5	17.5	30
1816-RTN	18	16	28.5	11.1	19.0	17.5	17.5	30
2016-RTN	20	16	31.7	11.9	19.0	19.0	19.5	44
2018-RTN	20	18	31.7	11.9	19.0	19.0	19.5	44
2218-RTN	22	18	36.0	13.8	25.4	21.7	21.5	62
2220-RTN	22	20	36.0	13.8	25.4	21.7	21.5	62
2418-RTN	24	18	38.2	14.0	25.4	23.5	23.5	90
2420-RTN	24	20	38.2	14.0	25.4	23.5	23.5	92
2622-RTN	26	22	41.3	15.8	25.4	24.7	25.5	138
2824-RTN	28	24	44.0	17.5	28.5	26.9	27.5	162

T-スロットナット (T型生材料)

T-SUTUFF

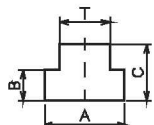

(寸法表)

No.	T・S	A	B	C	T	L	質量
10-TN	10	15.8	4.7	12.7	9.5	22	26
12-TN	12	17.5	5.5	12.7	11.7	22	32
14-TN	14	22.2	8.7	15.8	13.8	28	64
16-TN	16	25.4	8.7	15.8	15.8	28	73
18-TN	18	28.5	11.1	19.0	17.5	30	112
20-TN	20	31.7	11.9	19.0	19.7	30	128
22-TN	22	36.0	13.8	25.4	21.7	38	223
24-TN	24	38.2	14.0	25.4	23.5	38	239
28-TN	28	44.0	17.5	28.7	26.9	50	403