

# One Revolution Dial Gauges

## 0.001mm and 0.01mm Z series

- These are high-accuracy dial gauges with the pointer giving less than a full turn that can resist rigorous continuous measurement. The long stem is made of stainless steel, is high in strength and is malfunction-free due to fastening. The dial faces except No. 18 and 17B are easy to read with green and orange (dead zone)

### 0.001mm Type



**15Z**

Graduation: 0.001mm  
Range: 0.16mm

- Contact point (XB-1)
- Flat back



**15Z-SWF**

Graduation: 0.001mm  
Range: 0.16mm


- Contact point (XB-2A)
- Oil-proof type
- Flat back



**5Z-XB**

Graduation: 0.001mm  
Range: 0.14mm

- Contact point (XB-1)
- Flat back

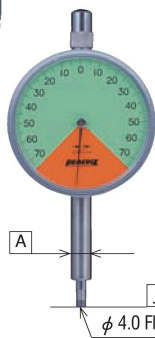

**5Z**

Graduation: 0.001mm  
Range: 0.14mm

- Long stem
- Flat back



**18**

Graduation: 0.001mm  
Range: 0.16mm

- Long stem
- Contact point (XB-1)
- Oil-proof type
- Flat crystal
- Flat back



New

**15DZ**

Graduation: 0.001mm  
Range: 0.16mm

- Large dial face (φ 66.5)
- Contact point (XB-1)
- Flat back

### 0.01mm Type



**17Z**

Graduation: 0.01mm  
Range: 0.8mm

- Contact point (XB-1)
- Flat back



**17Z-SWA**

Graduation: 0.01mm  
Range: 0.8mm


- Oil-proof type
- Contact point (XB-2)
- Flat back



**107Z-XB**

Graduation: 0.01mm  
Range: 0.8mm

- Long stem
- Contact point (XB-1)
- Flat back

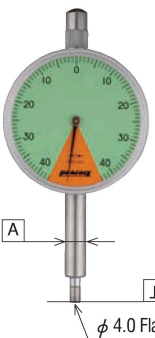

**107Z**

Graduation: 0.01mm  
Range: 0.8mm

- Long stem
- Flat back



**17B**

Graduation: 0.01mm  
Range: 0.8mm

- Contact point (X-1)
- Lug back




New

**117Z**

Graduation: 0.01mm  
Range: 1.0mm

- Contact point (XB-1)
- Flat back

### Miniature Type

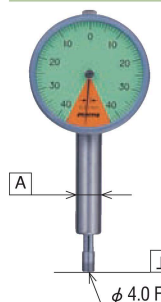

**47Z**

Graduation: 0.01mm  
Range: 0.8mm

- Long stem
- Flat back



**47Z-XB**

Graduation: 0.01mm  
Range: 0.8mm

- Contact point (XB-1)
- Flat back



**47SZ**

Graduation: 0.01mm  
Range: 0.8mm

- Contact point (XB-1)
- Flat back