


鋼 テーパーピン



D0000200

鉄

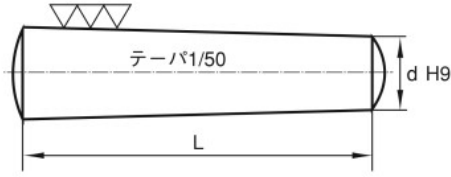

呼び径	2	2.5	3	4	5	6	7	8	10	12	30
基準寸法	2	2.5	3	4	5	6	7	8	10	12	30
d											
許容差		+0.025			+0.030			+0.036		+0.043	+0.052
		0			0			0		0	0

2.0		
長さ	入り数	生地
6	1000×1	●
8	1000×1	●
10	1000×1	●
12	1000×1	●
14	1000×1	●
15	1000×1	●
16	1000×1	●
18	1000×1	●
20	1000×1	●
22	1000×1	●
24	1000×1	●
25	1000×1	●
26	1000×1	●
28	1000×1	●
30	1000×1	●
32	1000×1	●
35	1000×1	●

2.5		
長さ	入り数	生地
6	1000×1	●
8	1000×1	●
10	1000×1	●
12	1000×1	●
14	1000×1	●
15	1000×1	●
16	1000×1	●
18	1000×1	●
20	1000×1	●
22	1000×1	●
24	1000×1	●
25	1000×1	●
26	1000×1	●
28	1000×1	●
30	500×1	●
32	500×1	●
35	500×1	●
36	500×1	●
40	500×1	●
45	500×1	●
50	500×1	●

3.0		
長さ	入り数	生地
6	1000×1	●
8	1000×1	●
10	1000×1	●
12	1000×1	●
14	1000×1	●
15	1000×1	●
16	1000×1	●
18	1000×1	●
20	1000×1	●
22	500×1	●
24	500×1	●
25	500×1	●
26	500×1	●
28	500×1	●
30	500×1	●
32	500×1	●
35	500×1	●
36	500×1	●
40	500×1	●
45	500×1	●
50	500×1	●
55	500×1	●
60	100×1	●

4.0		
長さ	入り数	生地
10	1000×1	●
12	1000×1	●
14	1000×1	●
15	1000×1	●
16	1000×1	●
18	500×1	●
20	500×1	●
22	500×1	●
24	500×1	●
25	500×1	●
26	100×1	●
28	100×1	●
30	100×1	●
32	100×1	●
35	100×1	●
36	100×1	●
40	100×1	●
45	100×1	●
50	100×1	●
55	100×1	●
60	100×1	●
65	100×1	●
70	100×1	●
75	100×1	●
80	100×1	●

5.0		
長さ	入り数	生地
15	500×1	●
16	500×1	●
18	500×1	●
20	500×1	●
22	100×1	●
24	100×1	●
25	100×1	●
26	100×1	●
28	100×1	●
30	100×1	●
32	100×1	●
35	100×1	●
36	100×1	●
40	100×1	●
45	100×1	●
50	100×1	●
55	100×1	●
60	100×1	●
65	100×1	●
70	100×1	●
75	100×1	●
80	100×1	●
90	100×1	●
100	100×1	●

6.0		
長さ	入り数	生地
15	100×1	●
16	100×1	●
18	100×1	●
20	100×1	●
22	100×1	●
24	100×1	●
25	100×1	●
26	100×1	●
28	100×1	●
30	100×1	●
32	100×1	●
35	100×1	●
36	100×1	●
40	100×1	●
45	100×1	●
50	100×1	●
55	100×1	●
60	100×1	●
65	100×1	●
70	100×1	●
75	100×1	●
80	100×1	●
90	100×1	●
100	50×1	●
110	50×1	●
120	50×1	●
130	50×1	●

7.0		
長さ	入り数	生地
25	100×1	●
30	100×1	●
32	100×1	●
35	100×1	●
40	100×1	●
45	100×1	●
50	100×1	●
55	100×1	●
60	100×1	●
65	100×1	●
70	100×1	●
75	50×1	●
80	50×1	●
90	50×1	●
100	50×1	●
120	50×1	●

8.0		
長さ	入り数	生地
20	100×1	●
22	100×1	●
24	100×1	●
25	100×1	●
26	100×1	●
28	100×1	●
30	100×1	●
32	100×1	●
35	100×1	●
36	100×1	●
40	100×1	●
45	100×1	●
50	100×1	●
55	50×1	●
60	50×1	●
65	50×1	●
70	50×1	●
75	50×1	●
80	50×1	●
90	50×1	●
100	50×1	●
110	50×1	●
120	50×1	●
130	50×1	●
140	50×1	●

10.0		
長さ	入り数	生地
25	100×1	●
26	100×1	●
28	100×1	●
30	100×1	●
32	50×1	●
35	50×1	●
36	50×1	●
40	50×1	●
45	50×1	●
50	50×1	●
55	50×1	●
60	50×1	●
65	50×1	●
70	50×1	●
75	50×1	●
80	50×1	●
90	30×1	●
100	30×1	●
110	30×1	●
120	30×1	●
130	30×1	●
140	30×1	●
150	30×1	●
160	30×1	●
180	25×1	●

12.0		
長さ	入り数	生地
30	50×1	●
32	50×1	●
35	50×1	●
36	50×1	●
40	50×1	●
45	50×1	●
50	50×1	●
55	50×1	●
60	30×1	●
65	30×1	●
70	30×1	●
75	25×1	●
80	25×1	●
90	25×1	●
100	25×1	●
110	25×1	●
120	25×1	●
130	25×1	●
140	25×1	●
150	25×1	●
160	25×1	●
180	25×1	●

30.0		
長さ	入り数	生地
55	10×1	●
60	10×1	●
65	10×1	●
70	10×1	●
75	10×1	●
80	10×1	●
90	5×1	●
100	5×1	●
110	5×1	●
120	5×1	●
130	5×1	●
140	5×1	●
150	5×1	●
160	5×1	●
180	5×1	●
200	5×1	●