


## 六角穴付止めねじ とがり先

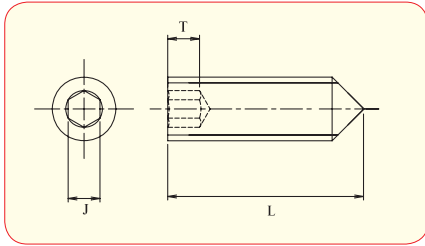

- 材質 ステンレスA2
- 表面処理 パシペート
- 規格 ANSI B18.3



RoHS指令適合商品



単位: インチ

呼び	#0	#1	#2	#3	#4	#5	#6	#8	#10	1/4	5/16	3/8	7/16	1/2	5/8	3/4	1
T 穴深さ	0.050	0.060	0.060	0.070	0.070	0.080	0.080	0.090	0.100	0.125	0.156	0.188	0.219	0.250	0.312	0.375	0.562
J 2面幅	0.028	0.028	0.035	0.050	0.050	1/16	1/16	5/64	3/32	1/8	5/32	3/16	7/32	1/4	5/16	3/8	9/16


サイズ		製品コード	標準 梱包
ねじの呼び	L		
#4-40	1/8	IN17.00440.010	100
	3/16	IN17.00440.015	100
	1/4	IN17.00440.020	100
#6-32	1/8	IN17.00632.010	100
	3/16	IN17.00632.015	100
	1/4	IN17.00632.020	100
	5/16	IN17.00632.025	100
#8-32	3/8	IN17.00632.030	100
	1/8	IN17.00832.010	100
	3/16	IN17.00832.015	100
	1/4	IN17.00832.020	100
#10-24	5/16	IN17.00832.025	100
	3/8	IN17.00832.030	100
	1/4	IN17.01024.020	100
	3/16	IN17.01024.015	100
#10-24	5/16	IN17.01024.025	100
	3/8	IN17.01024.030	100
	1/2	IN17.01024.040	100
	1/4	IN17.01024.020	100

サイズ		製品コード	標準 梱包
ねじの呼び	L		
#10-32	3/16	IN17.01032.015	100
	1/4	IN17.01032.020	100
	5/16	IN17.01032.025	100
	3/8	IN17.01032.030	100
	1/2	IN17.01032.040	100
1/4-20	1/4	IN17.02020.020	100
	5/16	IN17.02020.025	100
	3/8	IN17.02020.030	100
	1/2	IN17.02020.040	100
	5/8	IN17.02020.050	100
	3/4	IN17.02020.060	100
1	IN17.02020.100	100	

サイズ		製品コード	標準 梱包
ねじの呼び	L		
5/16-18	5/16	IN17.02518.025	100
	3/8	IN17.02518.030	100
	1/2	IN17.02518.040	100
	5/8	IN17.02518.050	100
	3/4	IN17.02518.060	100
3/8-16	1	IN17.02518.100	100
	3/8	IN17.03016.030	100
	1/2	IN17.03016.040	100
	5/8	IN17.03016.050	100
	3/4	IN17.03016.060	100
1	IN17.03016.100	100	

1本から販売致します。

## 六角穴付止めねじ 棒先

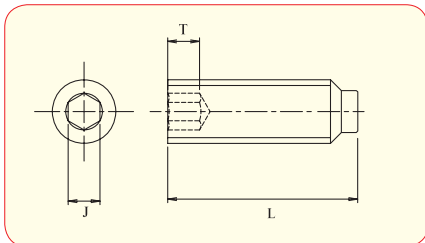

- 材質 ステンレスA2
- 表面処理 パシペート
- 規格 ANSI B18.3



RoHS指令適合商品



単位: インチ

呼び	#0	#1	#2	#3	#4	#5	#6	#8	#10	1/4	5/16	3/8	7/16	1/2	5/8	3/4	1
T 穴深さ	0.050	0.060	0.060	0.070	0.070	0.080	0.080	0.090	0.100	0.125	0.156	0.188	0.219	0.250	0.312	0.375	0.562
J 2面幅	0.028	0.028	0.035	0.050	0.050	1/16	1/16	5/64	3/32	1/8	5/32	3/16	7/32	1/4	5/16	3/8	9/16

サイズ		製品コード	標準 梱包
ねじの呼び	L		
#4-40	1/8	IN18.00440.010	100
	3/16	IN18.00440.015	100
	1/4	IN18.00440.020	100
#6-32	1/8	IN18.00632.010	100
	3/16	IN18.00632.015	100
	1/4	IN18.00632.020	100
	5/16	IN18.00632.025	100
#8-32	3/8	IN18.00632.030	100
	1/8	IN18.00832.010	100
	3/16	IN18.00832.015	100
	1/4	IN18.00832.020	100
#10-24	5/16	IN18.00832.025	100
	3/8	IN18.00832.030	100
	1/4	IN18.01024.020	100
	3/16	IN18.01024.015	100
#10-24	5/16	IN18.01024.025	100
	3/8	IN18.01024.030	100
	1/2	IN18.01024.040	100
	1/4	IN18.01024.020	100

サイズ		製品コード	標準 梱包
ねじの呼び	L		
#10-32	3/16	IN18.01032.015	100
	1/4	IN18.01032.020	100
	5/16	IN18.01032.025	100
	3/8	IN18.01032.030	100
	1/2	IN18.01032.040	100
1/4-20	1/4	IN18.02020.020	100
	5/16	IN18.02020.025	100
	3/8	IN18.02020.030	100
	1/2	IN18.02020.040	100
	5/8	IN18.02020.050	100
	3/4	IN18.02020.060	100
1	IN18.02020.100	100	

サイズ		製品コード	標準 梱包
ねじの呼び	L		
5/16-18	5/16	IN18.02518.025	100
	3/8	IN18.02518.030	100
	1/2	IN18.02518.040	100
	3/4	IN18.02518.060	100
	1	IN18.02518.100	100
3/8-16	3/8	IN18.03016.030	100
	1/2	IN18.03016.040	100
	5/8	IN18.03016.050	100
	3/4	IN18.03016.060	100
	1	IN18.03016.100	100

1本から販売致します。