


PIN-BUTTON HEAD TAPPING SCREWS



- **Material**
Stainless Steel A2
- **Thread**
Type AB

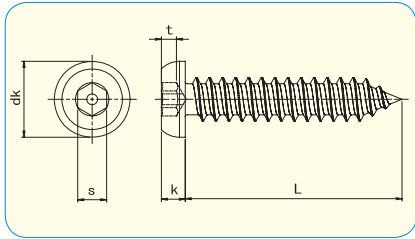

	3.5	4.2	4.8
dk	6.66	7.93	9.17
k	1.86	2.21	2.57
s	1/8	5/32	5/32
Drive Size	1/8	5/32	5/32



	SIZE		PART #	Box q'ty
	d	L		
ST3.5	10		HE033510	100
	13		HE033513	100
	16		HE033516	100
	20		HE033520	100
	25		HE033525	100
	38		HE033538	100
ST4.2	10		HE034210	100
	13		HE034213	100
	16		HE034216	100
	20		HE034220	100
	25		HE034225	100
	32		HE034232	100
	38		HE034238	100
	50		HE034250	100
ST4.8	13		HE034813	100
	16		HE034816	100
	20		HE034820	100
	25		HE034825	100
	32		HE034832	100
	38		HE034838	100
	50		HE034850	100

Please see page 40-41 for tools.